



LED SURFACE MOUNT DISK LIGHTS

WHITE

SUGGESTED APPLICATIONS

- Ceiling or surface mount, designed to install with most 4" junction boxes
- Suitable for use in clothes closets when installed in accordance with NFPA 70, NEC section 410.16 (A)(3) and 410.16 (C)(5)
- Suitable for damp and wet locations

FEATURES

- ENERGY STAR® Certified, highly energy efficient with efficacy up to 80 LPW
- T24 JA8: Can be used to comply with California Energy Commission's High Efficacy LED light source requirements
- Exceptional light quality with Color Rendering Index of 90
- Dimmable down to 10%



INPUT VOLTAGE: 120V

FREQUENCY: 60Hz

POWER FACTOR: >0.9

**DIMMABLE: PHASE CUT,
DOWN TO 10%**

EFFICACY: 80 LPW

CRI: 90

LIFETIME (L70): 50,000 HOURS

LOCATION RATING: WET

**AMBIENT OPERATING
TEMPERATURE: -4°F TO 104°F**

**CONSTRUCTION: ALUMINUM
HOUSING WITH WHITE
FINISH, SMOOTH FRAME AND
POLYCARBONATE LENS**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SURFACE MOUNT DISK LIGHTS

WHITE

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	INPUT CURRENT	CCT	BEAM ANGLE	ENERGY STAR
SDL4-11-930-D	73954	032886304804	900	11W	105mA	3000K	100°	Y
SDL4-11-940-D	73956	032886304811	900	11W	105mA	4000K	100°	Y
SDL6-15-930-D	73958	032886304828	1,200	15W	128mA	3000K	100°	Y
SDL6-15-940-D	73962	032886304835	1,200	15W	128mA	4000K	100°	Y

ORDERING GUIDE

Example: **SDL4-11-930-D**


PRODUCT	SIZE	WATTAGE	CRI	CCT	OPTIONS
SDL = SURFACE MOUNT DISK LIGHT	4 = 4" 6 = 6"	11 = 11 WATTS 15 = 15 WATTS	9 = 90 CRI	30 = 3000K 40 = 4000K	D = DIMMABLE

ENERGY SAVINGS *Based on 12 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
SDL4-11-9x0-D	11W	75W	39W	\$19	\$94
SDL6-15-9x0-D	15W	85W	60W	\$29	\$145

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
SDL4-11-9x0-D	5.98	1.22	0.31
SDL6-15-9x0-D	7.44	1.34	0.50

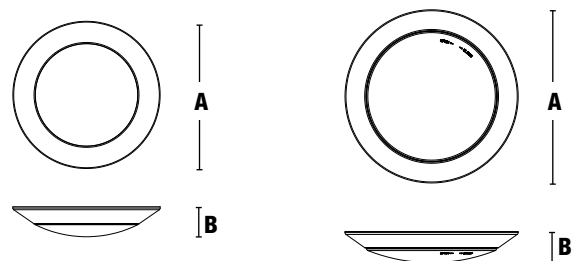

NOTES

Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 10%). Product performance may vary depending on dimmer manufacturer and circuit loading. Contact your local Southwire representative for a list of compatible dimmers.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>
This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.