



Southwire™

INSULATED BONDING BUSHINGS

CORROSION RESISTANT - ZINC DIE CAST

FEATURES

- Designed for superior protection against corrosion
- Tin plated copper lay-in lug
- Durable Zamak-3 Bushing
- UV Resistant liner for direct exposure to the sun
- Stainless steel hardware

APPLICATIONS


- Ideal for solar photovoltaic applications.
- Use to provide a means of grounding Rigid or IMC conduit
- Indoor or outdoor use (lay-in lug)
- Use lug provided for bonding jumper to a neutral bus bar
- Prevent damage to wire insulation with the UV resistant liner

STANDARD MATERIAL

- Body - Zinc (Zamak-3)
- Lug – Tin plated copper
- Clamping screw – Stainless steel
- Set screws – Stainless steel



332SL

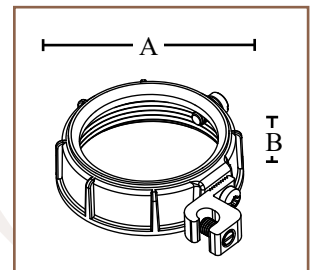

PART #	SIZE	GROUNDING LUG WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	RECOMMENDED TORQUE (IN - LBS)	A	B
		MIN.	MAX						
332SL	3/4"	14	4	10	100	11	35	1.26"	.41"
333SL	1"	14	4	5	50	7	35	1.53"	.50"
334SL	1-1/4"	14	4	5	50	8	35	1.86"	.53"
335SL	1-1/2"	14	4	5	50	9	35	2.13"	.56"
336SL	2"	14	4	5	50	12	35	2.60"	.66"
334ASL	1-1/4"	14	2/0	5	50	13	35	1.86"	.53"
335ASL	1-1/2"	14	2/0	5	50	14	35	2.13"	.56"
336ASL	2"	14	2/0	5	50	17	35	2.60"	.66"

Rev. 0, 05/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.