



Southwire™

EMT CONDUIT BODIES WITH COVER AND GASKET SET SCREW T TYPE

FEATURES

- Set screw T type with cover and gasket
- Suitable for use in concrete

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws
- Cover - Stamped steel
- Gasket - Neoprene rubber

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



ET1CG

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
ET1CG	1/2"	1	6 AWG	10	100	38	4.72"	1.37"	2.03"
ET2CG	3/4"	2	6 AWG	10	50	30	5.57"	1.625"	2.335"
ET3CG	1"	3	6 AWG	5	25	20	6.46"	1.90"	2.705"
ET4CG	1-1/4"	3	2 AWG	2	10	19	8.528"	2.77"	3.63"
ET5CG	1-1/2"	3	2 AWG	2	10	21	8.528"	2.77"	3.63"
ET6CG	2"	3	2/0 AWG	1	5	5	10.831"	3.335"	3.98"
ET7CG	2-1/2"	3	4/0 AWG	---	1	8	13.50"	4.06"	5.825"
ET8CG	3"	3	250 MCM	---	1	8	13.50"	4.685"	5.825"
ET9CG	3-1/2"	3	350 MCM	---	1	11	15.937"	5.45"	7.06"
ET10CG	4"	4	350 MCM	---	1	11	15.937"	5.45"	7.06"

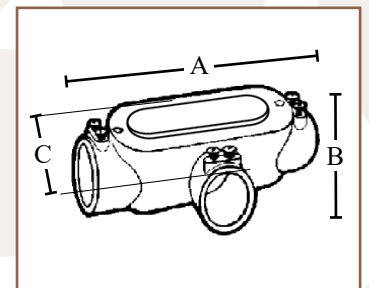

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.