



# Southwire™

## RIGID CONDUIT BODIES WITH COVER AND GASKET THREADED C TYPE

### FEATURES

- Threaded C type with cover and gasket
- NPT tapered hubs
- Suitable for use in concrete
- Suitable for use in wet locations

### APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

### STANDARD MATERIAL

- Copper free aluminum die cast
- Cover - Stamped steel
- Gasket - Neoprene rubber

### STANDARD FINISH

- Powder coat


### CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



C1CG

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
C1CG	1/2"	1	6 AWG	10	100	30	4.72"	1.37"	1.33"
C2CG	3/4"	2	6 AWG	10	50	25	5.57"	1.625"	1.54"
C3CG	1"	3	6 AWG	5	25	18	6.46"	1.90"	1.74"
C4CG	1-1/4"	3	2 AWG	2	10	17	8.528"	2.77"	2.49"
C5CG	1-1/2"	3	2 AWG	2	10	19	8.528"	2.77"	2.49"
C6CG	2"	3	2/0 AWG	1	5	14	10.831"	3.335"	3.10"
C7CG	2-1/2"	3	4/0 AWG	---	1	7	13.50"	4.06"	4.45"
C8CG	3"	3	250 MCM	---	1	7	13.50"	4.685"	4.45"
C9CG	3-1/2"	3	350 MCM	---	1	10	15.937"	5.45"	5.50"
C10CG	4"	4	350 MCM	---	1	10	15.937"	5.45"	5.50"

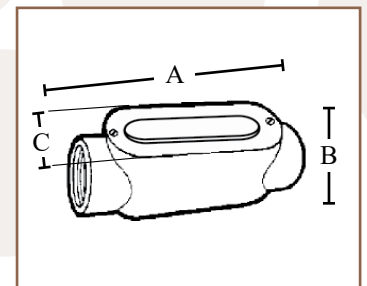

Rev. 0, 02/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.