



LED INDOOR REFLECTOR SERIES

PERFORMANCE SERIES BR30

SUGGESTED APPLICATIONS

- Track lighting, recessed downlighting
- Residential, multi-family, and office buildings

FEATURES

- 90 CRI provides exceptional color rendering
- Dimmable down to 5% of total light output
- Approximately 90% energy savings over halogen reflectors
- T20: Can be used to comply with California Energy Commission's Lighting Appliance Efficiency Regulations
- T24 JA8: 2700K, 3000K, and 4000K models can be used to comply with California Energy Commission's High Efficacy LED light source requirements

INPUT VOLTAGE: 120V

FREQUENCY: 60Hz

 
POWER FACTOR: >0.9

THD%: <20%

BASE: E26

**LENS TYPE:
SHATTER-RESISTANT PLASTIC**

**LIFETIME (L70):
UP TO 25,000 HOURS**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED INDOOR REFLECTOR SERIES

PERFORMANCE SERIES BR30

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	LUMENS PER WATT	BEAM ANGLE	CCT	CRI	CBCP (CD)
LBR30/8/927/D-46	73336	751338033856	650	7.5W	87	105°	2700K	90	220
LBR30/8/930/D-46	73337	751338033863	650	7.5W	87	105°	3000K	90	220
LBR30/8/940/D-46	73338	751338033870	650	7.5W	87	105°	4000K	90	220
LBR30/8/950/D-46	73339†	751338033887	650	7.5W	87	105°	5000K	90	220

ORDERING GUIDE

Example: **LBR30/8/927/D**


PRODUCT	WATTAGE	CRI	OPTIONS
LBR30 = LED BR30 Shape	8 = 8 Watts	927 = 90 CRI and 2700K 930 = 90 CRI and 3000K 940 = 90 CRI and 4000K 950 = 90 CRI and 5000K	D = Dimmable

ENERGY SAVINGS *Based on 6 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LBR30/8/9xx/D-46	7.5W	65W	57W	\$13.73	\$68.65

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
LBR30/8/9xx/D-46	5.2	3.7	.18

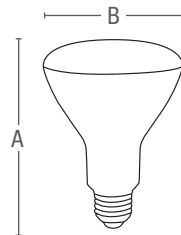

NOTES

†Not for sale in residential new construction in California.

*Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 10%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.southwire.com or contact your local Southwire representative for a list of compatible dimmers.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. Specifications subject to change without notice.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC: For details visit: <https://southwire.com/resources/warranties>

Specifications subject to change without notice.



800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.