



# Southwire™

## EMT AND RIGID COMBINATION CONDUIT BODIES

### LR TYPE

#### FEATURES

- Combination LR type
- NPT tapered hubs
- Suitable for use in concrete
- NEMA FB 1 rated for wet locations use with threaded rigid metal conduit only

#### APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

#### STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws

#### STANDARD FINISH

- Powder coat

#### CERTIFICATIONS


- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



LR1SS



| PART # | SIZE   | WIRE SIZE   |           | INNER QTY. | MASTER QTY. | WEIGHT/ CASE (LBS.) | A      | B     | C     |
|--------|--------|-------------|-----------|------------|-------------|---------------------|--------|-------|-------|
|        |        | MAX. NUMBER | MAX. SIZE |            |             |                     |        |       |       |
| LR1SS  | 1/2"   | 1           | 6 AWG     | 10         | 100         | 29                  | 4.56"  | 1.31" | 2.06" |
| LR2SS  | 3/4"   | 2           | 6 AWG     | 10         | 50          | 24                  | 5.31"  | 1.62" | 2.23" |
| LR3SS  | 1"     | 3           | 6 AWG     | 5          | 25          | 19                  | 6.25"  | 1.88" | 2.50" |
| LR4SS  | 1-1/4" | 3           | 2 AWG     | 2          | 10          | 14                  | 8.22"  | 2.50" | 3.40" |
| LR5SS  | 1-1/2" | 3           | 2 AWG     | 2          | 10          | 17                  | 8.22"  | 2.67" | 3.48" |
| LR6SS  | 2"     | 3           | 2/0 AWG   | ---        | 5           | 4                   | 10.48" | 3.29" | 4.07" |

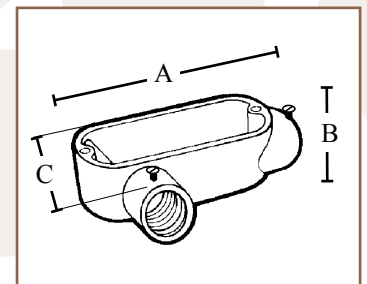

Rev. 0, 02/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.