



LED SURFACE MOUNT DISK LIGHT


CCT SELECTABLE

SUGGESTED APPLICATIONS

- Ceiling or surface mount, designed to install with most 4" junction boxes
- Suitable for use in closets, when installed in accordance with NEC requirements
- Suitable for damp and wet locations

FEATURES

- 5 CCT Selectable Switch: 2700K/3000K/3500K/4000K/5000K
- ENERGY STAR® Certified, highly energy efficient with efficacy up to 72 LPW
- T24 JA8: Can be used to comply with California Energy Commission's High Efficacy LED light source requirements
- Exceptional light quality with Color Rendering Index of 90
- High performance, long functional life of 50,000 hrs (L70)
- Smooth dimming down to 5%

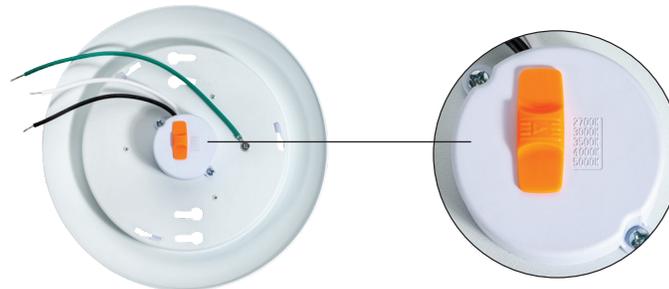

INPUT VOLTAGE: 120V

FREQUENCY: 60Hz

POWER FACTOR, THD %:
 $\geq 0.96, \leq 13\%$

DIMMABLE: PHASE CUT,
DOWN TO 5%

EFFICACY: 72 LPW

MINIMUM CRI: 90

FUNCTIONAL LIFE (L70):
50,000 HOURS

LOCATION RATING: WET

AMBIENT OPERATING
TEMPERATURE: -4°F TO 113°F



2700K 3000K
3500K 4000K 5000K

BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
 *Registered Trademark & ™ Trademark of Southwire Company, LLC.



LED SURFACE MOUNT DISK LIGHT

CCT SELECTABLE

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER	UPC	SIZE	LUMENS	WATTAGE	INPUT CURRENT	CCT	BEAM ANGLE	ENERGY STAR
WHITE									
SDL4/8W/WH/D/CTS-46	70722	751338037069	4"	580	8W	0.09A	2700K 3000K 3500K 4000K 5000K	110°	Y
SDL6/11W/WH/D/CTS-46	70723	751338037076	6"	770	11W	0.125A	2700K 3000K 3500K 4000K 5000K	110°	Y
SDL6/15W/WH/D/CTS-46	70724	751338037083	6"	1,000	15W	0.16A	2700K 3000K 3500K 4000K 5000K	110°	Y
BRONZE									
SDL4/8W/BZ/D/CTS-46	70768	751338038011	4"	580	8W	0.09A	2700K 3000K 3500K 4000K 5000K	110°	Y
SDL6/11W/BZ/D/CTS-46	70769	751338038028	6"	770	11W	0.125A	2700K 3000K 3500K 4000K 5000K	110°	Y
SDL6/15W/BZ/D/CTS-46	70770	751338038035	6"	1,000	15W	0.16A	2700K 3000K 3500K 4000K 5000K	110°	Y
BRUSHED NICKEL									
SDL4-8W-BN-D-CTS	73737	032886304842	4"	580	8W	0.09A	2700K 3000K 3500K 4000K 5000K	110°	Y
SDL6-11W-BN-D-CTS	73738	032886304859	6"	770	11W	0.125A	2700K 3000K 3500K 4000K 5000K	110°	Y
SDL6-15W-BN-D-CTS	73739	032886304866	6"	1,000	15W	0.16A	2700K 3000K 3500K 4000K 5000K	110°	Y

NOMENCLATURE

Example: **SDL4-8W-BN-D-CTS**

PRODUCT	SIZE	WATTAGE	COLOR	OPTIONS	CCT
SDL = SURFACE MOUNT DISK LIGHT	4 = 4" 6 = 6"	8W = 8 WATTS 11W = 11 WATTS 15W = 15 WATTS	WH = WHITE BZ = BRONZE BN = BRUSHED NICKEL	D = DIMMABLE	CTS = COLOR TEMPERATURE SELECTABLE





TOPAZ®

A Southwire Company


LED SURFACE MOUNT DISK LIGHT CCT SELECTABLE

ENERGY SAVINGS Based on 12 hours/day and \$0.11/kWh


MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
SDL4/8W/xx/D/CTS-46	8W	50W	42W	\$20	\$101
SDL4-8W-BN-D-CTS	8W	50W	42W	\$20	\$101
SDL6/11W/xx/D/CTS-46	11W	65W	54W	\$26	\$130
SDL6-11W-BN-D-CTS	11W	65W	54W	\$26	\$130
SDL6/15W/xx/D/CTS-46	15W	75W	60W	\$29	\$145
SDL6-15W-BN-D-CTS	15W	75W	60W	\$29	\$145

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
SDL4/8W/xx/D/CTS-46	5.43	1.77	0.30
SDL4-8W-BN-D-CTS	5.43	1.77	0.30
SDL6/11W/xx/D/CTS-46	7.48	1.89	0.46
SDL6-11W-BN-D-CTS	7.48	1.89	0.46
SDL6/15W/xx/D/CTS-46	7.48	1.89	0.46
SDL6-15W-BN-D-CTS	7.48	1.89	0.46

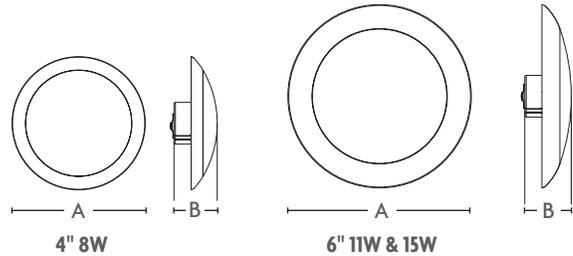

POLAR PLOTS

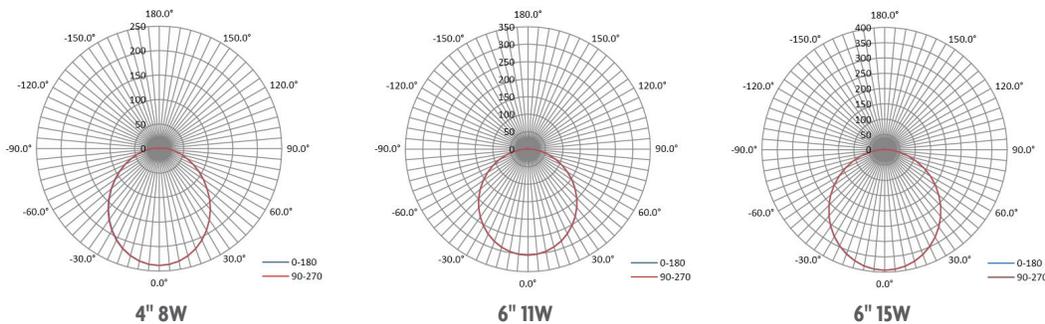

NOTES

Dimming - This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 5%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.
 FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>
 This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.
 Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
 *Registered Trademark & ™ Trademark of Southwire Company, LLC.