



Southwire™

RIGID RAIN TIGHT COUPLINGS

COMPRESSION TYPE - MALLEABLE IRON

FEATURES

- Raintight and concrete tight
- Compression type couplings
- Threadless
- Suitable for use with UL 6 & UL6 A Rigid Conduit
- For use with steel or aluminum conduit
- EZ slip on labor saving design
- No disassembly required

APPLICATION

- Use to join two lengths unthreaded Rigid or IMC conduit

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH


- Zinc plated



251MRT



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
251MRT	1/2"	10	100	32	2.16"	1.45"
252MRT	3/4"	10	100	40	2.30"	1.68"
253MRT	1"	5	50	29	2.68"	1.93"
254MRT	1-1/4"	5	50	42	3.02"	2.34"
255MRT	1-1/2"	---	12	13	3.16"	2.56"
256MRT	2"	---	5	9	3.33"	3.14"
257MRT	2-1/2"	---	5	17	4.38"	3.83"
258MRT	3"	---	3	12	4.74"	4.46"
259MRT	3-1/2"	---	2	11	4.86"	5.01"
260MRT	4"	---	2	12	5.29"	5.53"

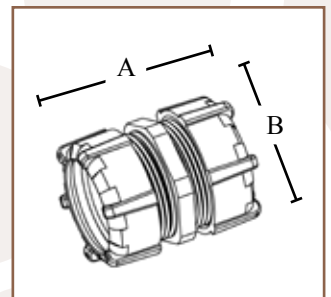

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.