



Southwire™

RIGID CONDUIT BODIES WITH COVER AND GASKET THREADED LL TYPE

FEATURES

- Threaded LL type with cover and gasket
- NPT tapered hubs
- Suitable for use in concrete
- Suitable for use in wet locations

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Cover - Stamped steel
- Gasket - Neoprene rubber

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



LL1CG

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
LL1CG	1/2"	1	6AWG	10	100	36	4.295"	1.37"	2.03"
LL2CG	3/4"	2	6AWG	10	50	23	5.09"	1.625"	2.33"
LL3CG	1"	3	6AWG	5	25	19	5.915"	1.90"	2.65"
LL4CG	1-1/4"	3	2AWG	2	10	15	7.894"	2.77"	3.385"
LL5CG	1-1/2"	3	2AWG	2	10	16	7.894"	2.77"	3.385"
LL6CG	2"	3	2/0AWG	1	5	14	10.134"	3.335"	3.81"
LL7CG	2-1/2"	3	4/0AWG	---	1	7	13"	4.063"	5.709"
LL8CG	3"	3	250MCM	---	1	7	12.75"	4.682"	5.506"
LL9CG	3-1/2"	3	350MCM	---	1	10	15.50"	5.452"	6.171"
LL10CG	4"	4	350MCM	---	1	10	15.50"	5.452"	6.171"

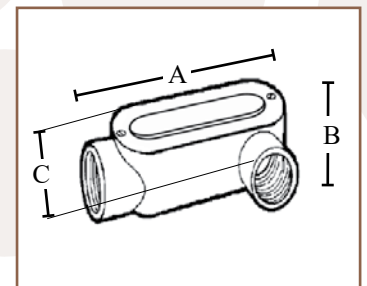

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.