



Southwire™

RIGID CONDUIT BODIES

THREADED T TYPE

FEATURES

- Threaded T type
- NPT tapered hubs
- Suitable for use in concrete
- Suitable for use in wet locations

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



T1

PART #	SIZE	WIRE SIZE MAX. NUMBER	MAX. SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
T1	1/2"	1	6 AWG	10	100	32	4.72"	1.37"	2.03"
T2	3/4"	2	6 AWG	10	50	26	5.57"	1.625"	2.335"
T3	1"	3	6 AWG	5	25	18	6.46"	1.90"	2.705"
T4	1-1/4"	3	2 AWG	2	10	17	8.528"	2.77"	3.63"
T5	1-1/2"	3	2 AWG	2	10	19	8.528"	2.77"	3.63"
T6	2"	3	2/0 AWG	---	5	7	10.831"	3.335"	3.98"
T7	2-1/2"	3	4/0 AWG	---	1	7	13.50"	4.06"	5.825"
T8	3"	3	250 MCM	---	1	7	13"	4.685"	5.825"
T9	3-1/2"	3	350 MCM	---	1	9	15.937"	5.45"	7.06"
T10	4"	4	350 MCM	---	1	9	15.937"	5.45"	7.06"

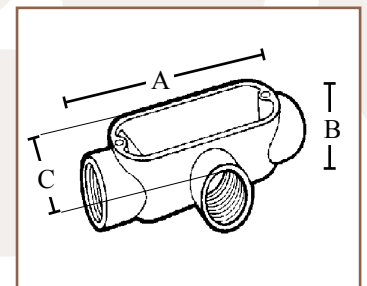

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.