



# Southwire™

## RIGID CONNECTORS

### COMPRESSION TYPE - MALLEABLE IRON

#### FEATURES

- Compression type connector
- Threadless
- Concrete tight

#### APPLICATION

- Dry location only
- Use to join unthreaded Rigid or IMC conduit to steel outlet box or metal enclosure

#### STANDARD MATERIAL

- Malleable iron

#### STANDARD FINISH

- Zinc plated

#### CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB 1-2014



261M



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
261M	1/2"	20	200	13	1.50"	1.50"
262M	3/4"	10	100	20	1.50"	1.63"
263M	1"	5	50	36	1.687"	2"
264M	1-1/4"	5	50	64	2"	2.38"
265M	1-1/2"	---	12	92	2.0625"	2.63"
266M	2"	---	12	117	2.25"	3.31"
267TZ	2-1/2"	---	5	14	3"	3.75"
268TZ	3"	---	3	13	3.125"	4.25"
269TZ	3-1/2"	---	2	13	3.187"	4.75"
270	4"	---	2	13	3.437"	5.312"
270A	5"	----	1	7	4.72"	6.86"
270B	6"	---	1	8	5.04"	8.14"

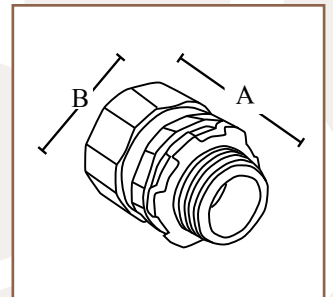

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.