



# Southwire™

## EMT AND RIGID COMBINATION CONDUIT BODIES LB TYPE

### FEATURES

- Combination LB type
- NPT tapered hubs
- Suitable for use in concrete
- NEMA FB 1 rated for wet locations use with threaded rigid metal conduit only

### APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

### STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws

### STANDARD FINISH

- Powder coat

### CERTIFICATIONS


- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



LB1SS



PART #	SIZE	WIRE SIZE MAX. NUMBER	MAX. SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
LB1SS	1/2"	1	6 AWG	10	100	28	4.56"	2.06"	1.31"
LB2SS	3/4"	2	6 AWG	10	50	19	5.31"	2.37"	1.48"
LB3SS	1"	3	6 AWG	5	25	18	6.25"	2.63"	1.75"
LB4SS	1-1/4"	3	2 AWG	2	10	13	8.22"	3.50"	2.40"
LB5SS	1-1/2"	3	2 AWG	2	10	14	8.22"	3.75"	2.40"
LB6SS	2"	3	2/0 AWG	---	5	13	10.13"	4.13"	3.10"

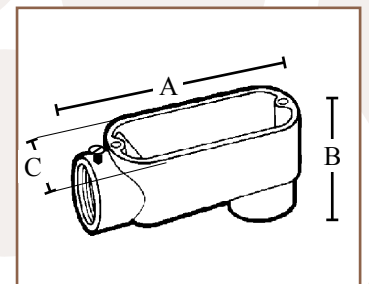

Rev. 0, 02/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.