



Southwire™

TOOLS & EQUIPMENT



# NEW INNOVATIVE SOLUTIONS

BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# DRIVERS

The newest additions to our screwdriver line have a chrome-plated finish for corrosion resistance. Built with heavy duty shanks and bolsters for wrench assisted turning and comfort grip handles for maximum torque, these screwdrivers make the perfect addition to your tool bag!

## ROTARY 4-IN-1 SCREWDRIVER

- Includes #1 & #2 Phillips and 3/16" & 1/4" slotted tips
- Magnetic Bit Holder
- Rotary design for faster screw installation
- Bit storage in handle



**SD4N1C**

## 6-IN-1 HEAVY DUTY NUT DRIVER

- Includes 3/16", 1/4", 5/16", 3/8", 7/16", and 9/16" nut drivers
- 62% more torque\*
- ASME B107.12-2004 color coded ends for quick identification
- Hollow shafts for screw clearance

\*Up to 62% more nut driver torque vs. previous generation of Southwire multi-bit nut driver shanks.



**ND6N1HD**

## ADJUSTABLE LENGTH SCREWDRIVER

- 2-in-1 includes #2 Phillips & 1/4" slotted tips
- Adjustable from 4" to 8"
- Pull collar down to extend, and pull up to shorten



**SD2N1AL**

## 6-IN-1 SCREWDRIVER WITH PRECISION BIT

- Includes 5/16" & 1/4" nut drivers, #1 & #0 Phillips tips, and 1/4" & 3/16" slotted tips
- #0 Phillips bit for precision work
- Precision-machined bits for an exact fit



**SD6N1P**

1-855-798-6657 | [SOUTHWIRETOOLS.COM](http://SOUTHWIRETOOLS.COM)

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & <sup>TM</sup>Trademark of Southwire Company, LLC.



## POCKET AND UTILITY KNIVES

Our line of knives are built for the job. Each knife features a lightweight metal body with comfort grip handles and premium blade materials that hold an edge over the competition. These knives are also covered under a no hassle, lifetime warranty.

### **EDGEFORCE™ HAWK BILL D2 KNIFE**

- Premium D2 stainless steel stays sharper longer
- Curved blade for pull cuts and splicing
- Stonewash black oxide coated blade for corrosion resistance
- Liner lock keeps blade secure
- Comfort grip for maximum hold and comfort
- Reversible belt clip
- Dual thumb studs for right or left hand opening



**HBKND2**

### **EDGEFORCE™ 3.25 DROP POINT D2 KNIFE**

- Premium D2 stainless steel stays sharper longer
- Drop point blade for everyday carry
- Stonewash Black oxide coated blade for corrosion resistance
- Liner lock keeps blade secure
- Reversible belt clip
- Dual thumb studs for right or left hand opening



**DPKD2**

# POCKET AND UTILITY KNIVES

## **EDGEFORCE™ COMPACT SHEEPS FOOT D2 KNIFE**

- Premium D2 stainless steel stays sharper longer
- Straight edge, sheeps foot blade is ideal for splicing
- Stonewash black oxide coated blade for corrosion resistance
- Liner lock keeps blade secure
- Compact size for everyday carry
- Reversible belt clip
- Dual thumb studs for right or left hand opening



**CSPKD2**

## **EDGEFORCE™ TANTO BLADE D2 KNIFE**

- Ideal for piercing, slicing, and tear cuts
- Fine and serrated edge for cutting and tearing
- Stonewash black oxide coated blade for corrosion resistance
- Liner lock keeps blade secure
- Dual thumb studs for right or left hand opening



**TBKND2-CAMO**

## **COMPACT POCKET KNIFE**

- Durable 8CR13MOV stainless steel blade
- Drop point blade and compact size for everyday carry
- Black oxide coated blade for corrosion resistance
- Liner lock keeps blade secure
- Reversible belt clip
- Dual thumb studs for right or left hand opening



**CDPK**



## POCKET AND UTILITY KNIVES

### HAWK BILL FOLDING KNIFE

- Durable 8CR13MOV stainless steel
- Curved blade for pull cuts and splicing
- Black oxide coated blade for corrosion resistance
- Liner lock keeps blade secure
- Comfort grip for maximum hold and comfort
- Reversible belt clip
- Dual thumb studs for right or left hand opening



**HBKN**

### QUICK OPEN FOLDING UTILITY KNIFE

- Quick open button for easy one hand operation
- Easy, tool-free blade change
- Accepts all common 2-point utility blades
- Comfort grip for maximum hold and comfort



**UTILQO**

### AUTO-RETRACTING SAFETY UTILITY KNIFE

- Auto-retract blade for safety
- Easy, tool-free blade change
- Accepts all common 2-point utility blades



**UTILAR**

# MULTIMETERS

Our newest multimeters are designed for a variety of applications. With a CAT III safety rating, these meters are great to use on the job.

## MANUAL RANGING MULTIMETER

- 600V AC/DC voltage range
- CAT III 300V safety rating
- Built-in test lead holder
- 7 functions



10031S

## AUTORANGING MULTIMETER

- 600V AC/DC voltage range
- CAT III 600V safety rating
- Non-contact voltage detector
- Built-in test lead holder
- 12 functions



10041N

## MULTIMETER ELECTRICAL TESTER KIT

- Receptacle Tester – Tests standard 120V AC outlets
- Multimeter – 600V AC/DC voltage range
- Non-Contact Voltage Tester – 90-1000V detection range



10037K



## TESTERS

Our newest receptacle and voltage testers perform multiple tests with one tool. Ideal for use on standard outlets.

### RECEPTACLE TESTER

- Tests standard 120V AC outlets
- 6 tests in 1



40012S

### GFCI RECEPTACLE TESTER

- Tests standard 120V AC outlets
- Tests GFCI outlets
- 7 tests in 1



40022S

### AC/DC VOLTAGE TESTER

- 120-480V AC voltage range
- 160-600V DC voltage range
- CAT III 600V safety rating



40141S

## AC LINE SPLITTER

The AC Line Splitter allows you to take current measurements without separating conductors. It features a CAT III safety rating and is UL listed.

- CAT III 300V safety rating
- UL listed design
- 14-gauge wire construction
- 10X resolution



60040S



## DRIVERS

UPC	Stock #	Model #	Description
032886699382	65028701	ND6N1HD	ND6N1HD, 6 IN 1 NUT DRIVER HVY DTY (TRI)
032886699375	65028601	SD2N1AL	SD2N1AL, 2 IN 1 ADJUSTABLE LENGTH DRIVER
032886699368	65028501	SD4N1C	SD4N1C, 4 IN 1 CRANK SCREWDRIVER
032886699399	65028801	SD6N1P	SD6N1P, 6 IN 1 DRIVER W/P#0 (TRI)

## UTILITY & POCKET KNIVES

UPC	Stock #	Model #	Description
032886699481	65029801	TBKND2-CAMO	TBKND2-CAMO, EDGEFORCE™ TANTO BLD FLD KNF CMO (TRI)
032886699467	65029601	HBKND2	HBKND2, EDGEFORCE™ HAWKBILL FOLDING KNF D2 (TRI)
032886699450	65029501	DPKD2	DPKD2, EDGEFORCE™ DROP POINT FLD KNF D2 (TRI)
032886699474	65029701	CSPKD2	CSPKD2, EDGEFORCE™ CMPCT SHEEPSFT FLD KNF D2 (TRI)
032886699443	65029401	HBKN	HBKN, HAWKBILL FOLDING KNF (TRI)
032886699436	65029301	CDPK	CDPK, CMPCT DROP POINT PKT KNF (TRI)
032886699412	65029001	UTILQO	UTILQO, QUICK OPN FOLDING UTIL KNF (TRI)
032886699429	65029201	UTILAR	UTILAR, AUTO RETRACT UTIL KNF (TRI)

## MULTIMETERS

UPC	Stock #	Model #	Description
032886699764	65031101	10031S	MANUAL RANGING MULTIMETER
032886699771	65031201	10041N	AUTORANGING MULTIMETER
032886699788	65031301	10037K	MULTIMETER ELECTRICAL TESTER KIT



**Southwire**<sup>TM</sup> TOOLS & EQUIPMENT


## TESTERS

UPC	Stock #	Model #	Description
032886699832	65031901	40012S	RECEPTACLE TESTER
032886699849	65032001	40022S	GFCI RECEPTACLE TESTER
032886699863	65032201	40141S	AC/DC VOLTAGE TESTER

## AC LINE SPLITTER

UPC	Stock #	Model #	Description
032886699887	65032401	60040S	AC LINE SPLITTER

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

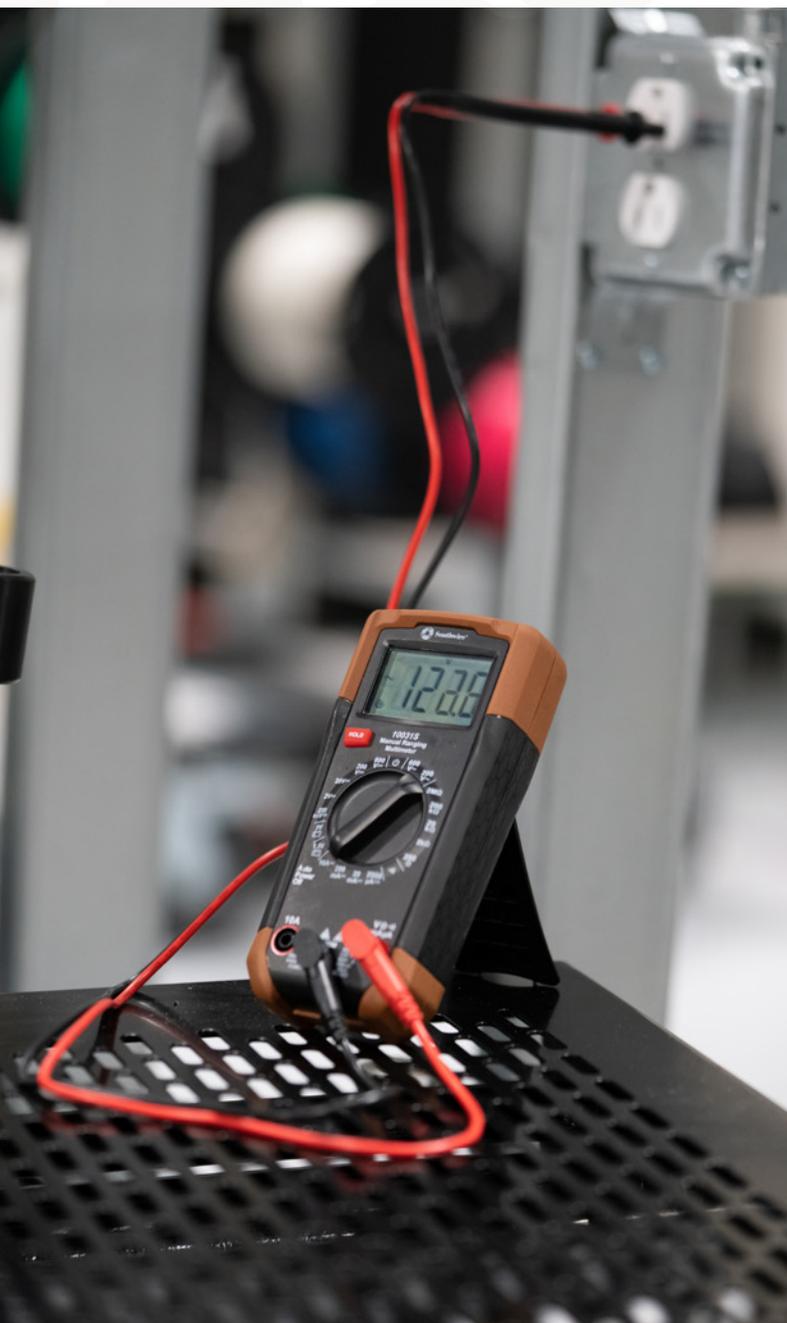



Southwire™

TOOLS & EQUIPMENT



GET SOCIAL WITH US:



/SOUTHWIRETOOLS  
/SOUTHWIRETOOLSLATINO



@SOUTHWIRETOOLS



@SOUTHWIRETOOLS



SOUTHWIRETOOLS

BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.