




Southwire™

MPHSP

MAX PUNCH™ HSP Hydraulic Stud Punch

THE MAX PUNCH™ HSP HYDRAULIC STUD PUNCH IS DESIGNED TO QUICKLY PUNCH HOLES THROUGH 16 GAUGE STRUCTURAL STEEL STUDS. THE MULTIFACETED DESIGN ALLOWS THE HSP TO EASILY ADJUST FOR 3 5/8" AND 6" STUDS AS WELL AS PUNCH 7/8" OR 1 11/32" HOLES.

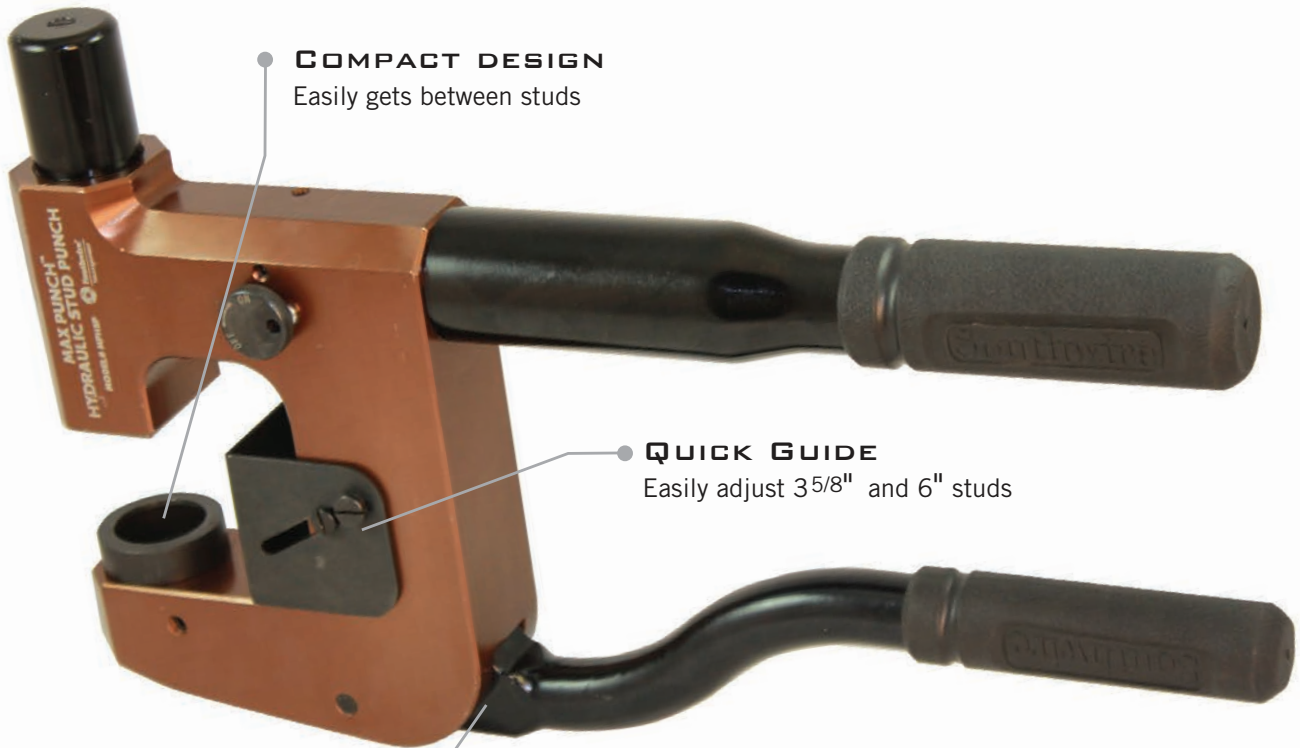

● **COMPACT DESIGN**
Easily gets between studs

● **QUICK GUIDE**
Easily adjust 3 5/8" and 6" studs

● **HEAVY GAUGE CAPABILITY**
Punches holes in up to 16 gauge structural steel studs

● **4 TOOLS IN 1**
Punches 7/8" and 1 11/32" holes



Southwire™

TOOLS & EQUIPMENT

[BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.]

1-855-SWT00LS
(855-798-6657)




Southwire™

MPHSP

MAX PUNCH™ HSP Hydraulic Stud Punch

4 TOOLS IN 1

ADJUSTABLE FOR 3 5/8" AND 6" STUDS, PUNCHES 7/8" OR 1 11/32" HOLES.

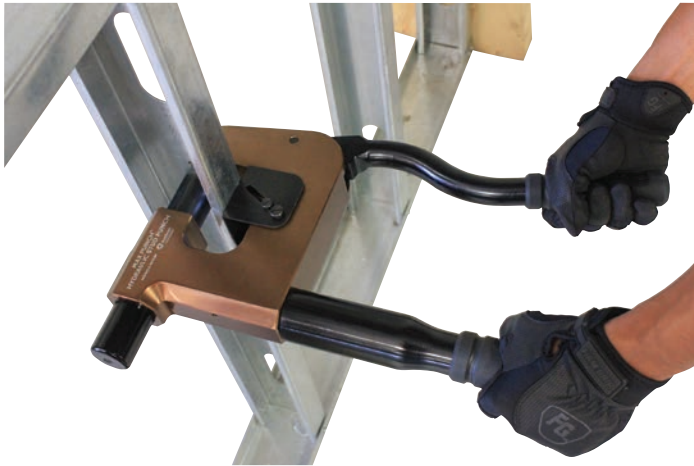

- PUNCHES HOLES IN 16 GAUGE STRUCTURAL STEEL STUDS
- COMPACT DESIGN FITS IN TIGHT SPACES
- PADDED HANDLES PROVIDE GRIPPING COMFORT AND GREATER CONTROL
- HEAVY DUTY CARRYING CASE



Model #	MPHSP
Stock #	58946501
Description	Hydraulic Stud Punch
Width	10.5"
Length	17.5"
Weight	11lbs
Warranty	1-Year
Capacity	Knock out size - 7/8" or 1 11/32" in 16 gauge steel



Southwire™

TOOLS & EQUIPMENT

[BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.]

1-855-SWT00LS

(855-798-6657)