



Southwire™

SIMpull™ FISH TAPE 240' TUBE

TWO LEADER OPTIONS

Includes both a 360° swiveling flexible metal leader and a non-conductive glow in the dark leader, one on either end

TAPERED TIP

Reduces the likelihood of snagging on wires & conduit when reeling-in the fish tape

FLEXIBLE METAL LEADER

Easily glides through conduit bends and around existing wire

LASER ETCHED FOOT MARKINGS


Identify conduit run lengths with incremental foot markings
Length increments begin at 1 Foot starting from the NCT side

IMPROVED PUSH

5.5mm tape works well in conduit up to 3 inches
4.5mm tape works well in conduit up to 2 inches



SCAN TO SEE MORE

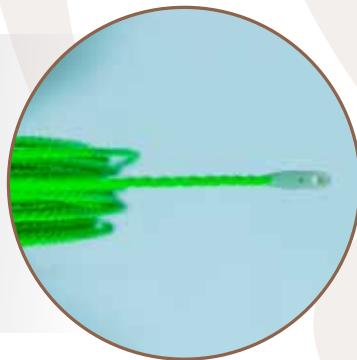

DURABILITY CERTIFIED



MODEL #	STOCK #	UPC #	DESCRIPTION	HEIGHT	WIDTH	DEPTH	WEIGHT
FTSP55-240FMLT	67015840	032886751226	240' SIMpull™ Tube Fish Tape with both FML & NCT Tips 5.5m	24"	24"	4"	4.3 lbs
FTSP45-240FMLT	63164740	032886964770	240' SIMpull™ Tube Fish Tape with both FML & NCT Tips 4.5m	24"	24"	4"	4.3 lbs
FTSP4.5FML-LRKIT	64277640	032886985942	SIMpull™ Replacement Leader Kit, 2x of each Leader Included	6"	17"	4"	2.6 lbs

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2021 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.