



# Southwire™

## RIGID RAIN TIGHT CONNECTORS

### COMPRESSION TYPE WITH INSULATED THROAT - STEEL

#### FEATURES

- Raintight
- Compression type connector
- Insulated throat
- Threadless
- Suitable for use with UL 6 Rigid Conduit
- For use with steel conduit
- EZ slip-on labor saving design
- No disassembly required

#### APPLICATION

- Use to join unthreaded Rigid or IMC conduit to steel outlet box or metal enclosure

#### STANDARD MATERIAL

- Body/Gland Nut: Steel/Zinc plated
- Gasket/Insulator: High performance thermoplastics
- Locknut: Steel/Zinc plated

#### STANDARD FINISH

- Body/Gland Nut: Steel/Zinc plated
- Gasket/Insulator: High performance thermoplastics
- Locknut: Steel/Zinc plated

#### CERTIFICATIONS


- UL Standard: UL 514B



261SIRT



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
261SIRT	1/2"	20	200	35	1.62"	1.23"
262SIRT	3/4"	10	100	25	1.69"	1.50"
263SIRT	1"	5	50	20	2"	1.80"
264SIRT	1-1/4"	5	50	39	2.21"	2.21"
265SIRT	1-1/2"	---	12	9	2.28"	2.44"
266SIRT	2"	---	12	12	2.44"	3"

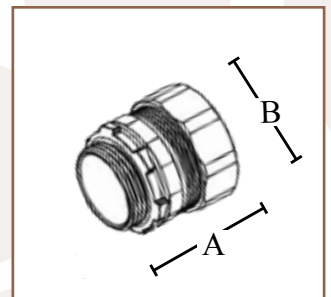

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.