



Southwire™

EMT AND RIGID COMBINATION CONDUIT BODIES WITH COVER AND GASKET

LB TYPE

FEATURES

- Combination LB type with cover and gasket
- NPT tapered hubs
- Suitable for use in concrete
- NEMA FB 1 rated for wet locations use with threaded rigid metal conduit only

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Cover - Stamped steel
- Gasket - Neoprene rubber

STANDARD FINISH

- Powder coat

CERTIFICATIONS


- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



LB1SSCG



PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
LB1SSCG	1/2"	1	6 AWG	10	100	34	4.56"	2.06"	1.31"
LB2SSCG	3/4"	2	6 AWG	10	50	23	5.31"	2.37"	1.48"
LB3SSCG	1"	3	6 AWG	5	25	19	6.25"	2.63"	1.75"
LB4SSCG	1-1/4"	3	2 AWG	2	10	14	8.22"	3.50"	2.40"
LB5SSCG	1-1/2"	3	2 AWG	2	10	15	8.22"	3.75"	2.40"
LB6SSCG	2"	3	2/0 AWG	---	5	14	10.13"	4.28"	3.10"

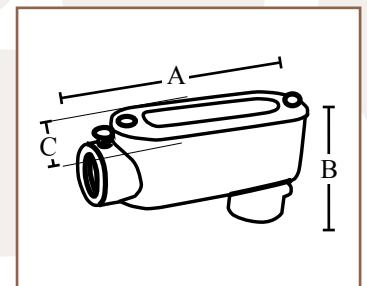

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.