

LED Slim Fit Recessed Downlights

DEEP REGRESSED - CCT SELECTABLE



SUGGESTED APPLICATIONS

- Retrofit and new construction
- Commercial, residential and multi-family buildings
- Low clearance areas, closets, stairwells, soffits, bathroom, and living areas

FEATURES

- 5 CCT selectable switch: 2700K, 3000K, 3500K, 4000K and 5000K
- Deep regress reflector provides low glare and comfortable uniform optical distribution
- Strong low profile design with white aluminum trim and polycarbonate lens
- Easy to install with spring clips and quick-connects without the need of housings
- Spacious remote J-box provides flexibility in mounting
- IC Rated, approved for use in insulated ceiling and non-insulated ceiling
- Airtight certified per ASTM-E283
- T24 JA8: Can be used to comply with California Energy Commission's High Efficacy LED light source requirements



LED SLIM FIT RECESSED DOWNLIGHTS

DEEP REGRESSED - CCT SELECTABLE

GENERAL SPECIFICATIONS

Input Voltage/Frequency: 120v, 60Hz
Power Factor, THD %: >0.94, <18%
Dimmable: Phase cut, Down to 5%
Efficacy: up to 83 LPW

Minimum CRI: 90
Functional Life (L70): 50,000 hours
Location Rating: Wet location
Ambient Operating Temperature: -4°F to 113°F

Suitable For Bathroom Applications
IC Rated
AT Rated

ITEM SPECIFICATIONS / ORDER INFO

Model #	Order Code	UPC	Lumens	Wattage	Input Current	CCT	Beam Angle	CA T24 JA8
Smooth								
DLD4S-7CS	73287	032886300196	580	7W	70mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6S-10CS	73289	032886300202	770	10W	90mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6S-13CS	73291	032886300219	1,000	13W	125mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6S-16CS	73293	032886300226	1,200	15.5W	145mA	2700K/3000K/3500K/4000K/5000K	110°	Y
Baffle								
DLD4B-7CS	73299	032886300233	580	7W	70mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6B-10CS	73301	032886300240	770	10W	90mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6B-13CS	73303	032886300257	1,000	13W	125mA	2700K/3000K/3500K/4000K/5000K	110°	Y
DLD6B-16CS	73305	032886300264	1,200	15.5W	145mA	2700K/3000K/3500K/4000K/5000K	110°	Y

NOMENCLATURE


DLD4S-7CS: DLD = Downlight LED Deep Regress **4** = 4" **S** = Smooth **7** = 7 Watts **CS** = 5 Color Temperature Selectable
6 = 6" **B** = Baffle **10** = 10 Watts
13 = 13 Watts
16 = 15.5 Watts

ENERGY SAVINGS Based on 12 hours/day and \$0.11/kWh

Model #	LED Wattage	Incandescent Replacement Wattage	Watts Saved	Yearly Savings	5 Year Savings
DLD4X-7CS	7W	50W	43W	\$21	\$104
DLD6X-10CS	10W	65W	55W	\$26	\$132
DLD6X-13CS	13W	75W	62W	\$30	\$149
DLD6X-16CS	15.5W	85W	69.5W	\$33	\$167

DIMENSIONS/WEIGHTS

Model #	A	B	C	D	E	F	Weight (lbs)
DLD4X-XCS	5.28"	1.73"	3"	4.50"	5.45"	1.36"	0.75
DLD6X-XCS	7.09"	1.78"	3"	4.50"	5.45"	1.36"	0.86

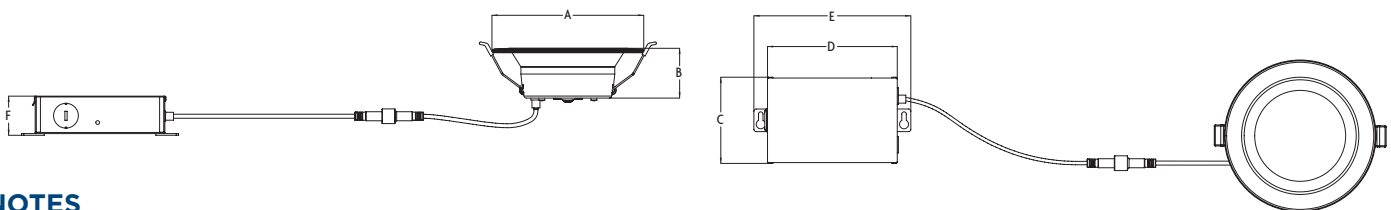

NOTES

Dimming - This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 5%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC: For details visit: <https://southwire.com/resources/warranties>

Specifications subject to change without notice.

Rev. 0, 07/22