



Southwire™

STRUT CLAMPS

ONE PIECE STRUT CLAMP

APPLICATION

Secures electrical conduit or cable perpendicular to strut

FEATURES

Design has no screws or bolts to drop as you fit it to the strut channel

Hex/slotted/Phillips bolt 1/4"-20 thread

MATERIAL/FINISH

Steel/Galvanized

CERTIFICATIONS


UL Listed

UL Standard: UL 2239



SCH12BTZ

SCH12TZ

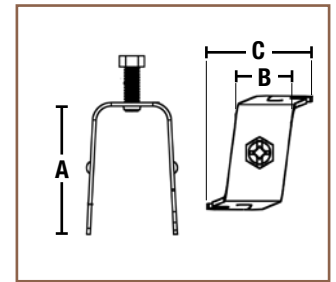

PART #	BOOT FEATURE	EMT SIZE	RIGID SIZE	STATIC LOAD	A	B	C	BOX QTY.
SCH8TZ	NO BOOT	1/2"	---	200	1.87"	.75"	1.34"	100
SCH12TZ	NO BOOT	3/4"	1/2"	200	2.13"	.75"	1.38"	100
SCH16TZ	NO BOOT	1"	3/4"	200	2.24"	.75"	1.38"	100
SCH20TZ	NO BOOT	1-1/4"	1"	200	2.48"	.75"	1.38"	100
SCH6BTZ	BOOT	3/8"	---	200	1.55"	.75"	1.22"	100
SCH8BTZ	BOOT	1/2"	---	200	1.87"	.75"	1.34"	100
SCH12BTZ	BOOT	3/4"	1/2"	200	2.13"	.75"	1.38"	100
SCH16BTZ	BOOT	1"	3/4"	200	2.24"	.75"	1.38"	100
SCH20BTZ	BOOT	1-1/4"	1"	200	2.48"	.75"	1.18"	100
SCH24BTZ	BOOT	1-1/2"	1-1/4"	350	2.78"	.75"	1.2"	50
SCH32BTZ	BOOT	2"	1-1/2"	350	3.29"	.75"	1.2"	50
SCH40BTZ	BOOT	---	2"	350	3.46"	.75"	.93"	50
SCH48BTZ	BOOT	2-1/2"	2-1/2"	350	4"	.75"	.83"	24
SCH56BTZ	BOOT	3"	3"	350	4.57"	.75"	.75"	25
SCH64BTZ	BOOT	3-1/2"	3-1/2"	350	5.12"	.75"	.75"	10
SCH72BTZ	BOOT	4"	4"	350	5.67"	.75"	.75"	10

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.