


Steady arm G1" straight with insulation 3 kV, adjustable, L = 1500 mm, with thread 5/8", SST

Item number D2445-02

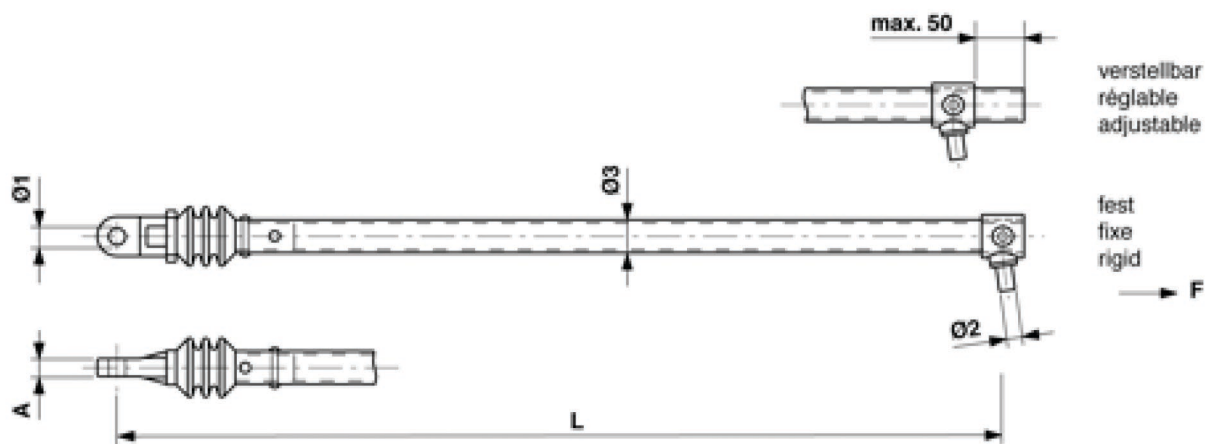

Dimensions

$\varnothing 2$: 5/8"
 $\varnothing 1$: 17 mm
L: 1500 mm
A: 18 mm
 $\varnothing 3$: 33.7 mm

Material and weight

Weight: 4.380 kg
Material: SST

Loads

Breaking load F: 6.4 kN

Specification

Minimum creeping distance: 85 mm for insulator
Operating voltage: max. 3000 V

Comments

- Steady arm G1" are also available in aluminum (with reduced breaking load and low weight)
- Minimum order quantity on request
- Other lengths on request



Southwire[™]



A COLAS RAIL COMPANY

Contact Us: Transit@southwire.com