



Southwire™

RIGID CONDUIT BODIES WITH COVER AND GASKET THREADED T TYPE

FEATURES

- Threaded T type with cover and gasket
- NPT tapered hubs
- Suitable for use in concrete
- Suitable for use in wet locations

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Cover - Stamped steel
- Gasket - Neoprene rubber

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



T1CG

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
T1CG	1/2"	1	6 AWG	10	100	38	4.72"	1.37"	1.33"
T2CG	3/4"	2	6 AWG	10	50	30	5.57"	1.625"	1.54"
T3CG	1"	3	6 AWG	5	25	20	6.46"	1.90"	1.74"
T4CG	1-1/4"	3	2 AWG	2	10	19	8.528"	2.77"	2.49"
T5CG	1-1/2"	3	2 AWG	2	10	21	8.528"	2.77"	2.49"
T6CG	2"	3	2/0 AWG	---	5	10	10.831"	3.335"	3.10"
T7CG	2-1/2"	3	4/0 AWG	---	1	4	13.50"	4.06"	5.825"
T8CG	3"	3	250 MCM	---	1	5	13.50"	4.685"	5.825"
T9CG	3-1/2"	3	350 MCM	---	1	12	15.937"	5.45"	7.06"
T10CG	4"	4	350 MCM	---	1	9	15.937"	5.45"	7.06"

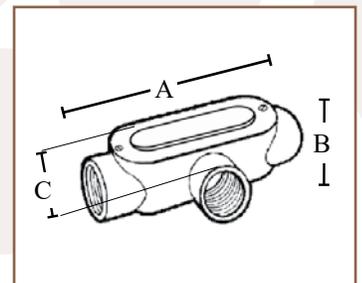

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.