



Southwire™

RIGID CABLE SUPPORT BODY

HOT DIP GALVANIZED- MALLEABLE IRON

FEATURES

- Threaded for Rigid Conduit and IMC
- Tapered inside surface is knurled to grip cable
- For two or more wires
- Cable Support Wood Chock is sold separately
- For use with threadless conduit or EMT, when used with male end threadless connector
- Use with all types of insulations at 600V

APPLICATIONS

- Use to support non-armored electrical cables in vertical conduit risers

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH

- Hot dip galvanized

CERTIFICATIONS

- UL 514B
- RoHS
- Fed. Spec. A-A-50553
- NEMA FB 1




CSB7



Conforms to finish thickness
ASTM A123/123M

| PART # | SIZE | MASTER QTY. | WEIGHT/ CASE (LBS.) | A | B |
|--------|--------|-------------|---------------------|-------|-------|
| CSB5 | 1-1/2" | 20 | 20 | 2.60" | 2.19" |
| CSB6 | 2" | 10 | 17 | 3.19" | 2.36" |
| CSB7 | 2-1/2" | 10 | 19 | 3.61" | 2.57" |
| CSB8 | 3" | 10 | 25 | 4.30" | 2.78" |
| CSB9 | 3-1/2" | 5 | 19 | 4.96" | 3.11" |
| CSB10 | 4" | 5 | 25 | 5.51" | 3.36" |

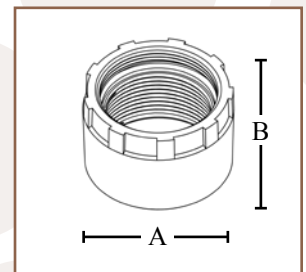

Rev. 0, 05/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.