



# Southwire™

## 15A RIGHT ANGLE CORD SETS (TRIPLE RECEPTACLE)

Shockshield right angle GFCI ensures protection from dangerous current leakage that can cause electrical shock and possible electrocution.



**GFCI WITH 4-6MA TRIP POINT**

**25MS TRIP RESPONSE TIME**

**MANUAL RESET**

**PROVIDES COMPLIANCE WITH  
NEC 2008 ARTICLE 590.6 FOR  
TEMPORARY INSTALLATIONS**

**CUSTOM CABLE GAUGES, LENGTHS  
AND TERMINATIONS AVAILABLE BY  
SPECIAL ORDER**

**APPLICATIONS: PLANT  
MAINTENANCE, EQUIPMENT  
SERVICE AND CONSTRUCTION SITES**



**14880004-6**

APPLICATIONS
High Pressure
Sprayer Washers
Power Tools
Drain Snakes
Pumps
Construction Sites
Industrial Appliances
Saws and Drills
Portable Electric Power Tools
Multiple Tools

MODEL #	ELECTRICAL RATING			CORD LENGTH	CORD GAUGE	WIRE TYPE	COLOR	RECEPTACLE COUNT	LIGHTED RECEPTACLE
14880023-6	120V	15A	60Hz	2'	12/3 AWG	SJTW	YELLOW	TRIPLE	YES
14880004-6	120V	15A	60Hz	6'	12/3 AWG	SJTW	YELLOW	TRIPLE	NO
14880118-2	120V	15A	60Hz	25'	12/3 AWG	SJTW	YELLOW	TRIPLE	NO
14880119-1	120V	15A	60Hz	50'	12/3 AWG	SJTW	YELLOW	TRIPLE	NO
14880120-1	120V	15A	60Hz	99'	12/3 AWG	SJTW	YELLOW	TRIPLE	NO
14880228-6	120V	15A	60Hz	25'	12/3 AWG	SJEOW	YELLOW	TRIPLE	NO
14880229-6	120V	15A	60Hz	50'	12/3 AWG	SJEOW	YELLOW	TRIPLE	NO
14880230-4	120V	15A	60Hz	100'	12/3 AWG	SJEOW	YELLOW	TRIPLE	NO

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**




**1-855-798-6657 | SOUTHWIRE.COM**

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# Southwire™

TECHNICAL DATA	
GROUNDING NEUTRAL	4 Ohms Typical
VOLTAGE SURGE WITHSTAND	3 Kv Ringwave Test and 4Kv/2Ka Surge Immunity Test
RADIO FREQUENCY NOISE SUSCEPTABILITY	Operates Within Normal Limits With 0.5 Volts Injected On Power Line 150Khz-230Mhz
ENDURANCE	3,000 Operations Minimum
OVERLOAD CURRENT	Six Times Rated Current
OPERATING TEMPERATURE RANGE	-35°C to 66°C
EFFECT OF 10 AMP TURN DC SOCK FAULT TRIP	5% Maximum Trip Level Variation on Ground
INSULATION VOLTAGE	1500 Vrms - 1 Min.
POWER INDICATION	Mechanical Indicator

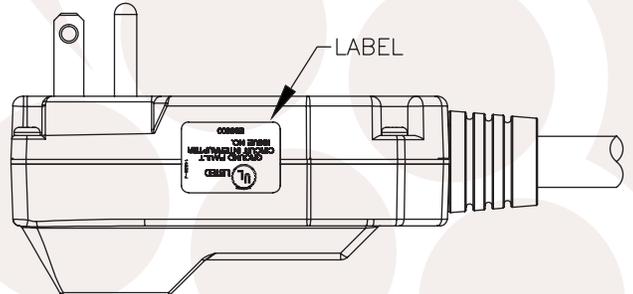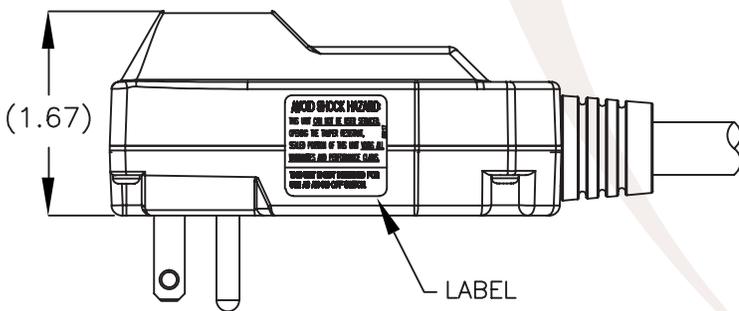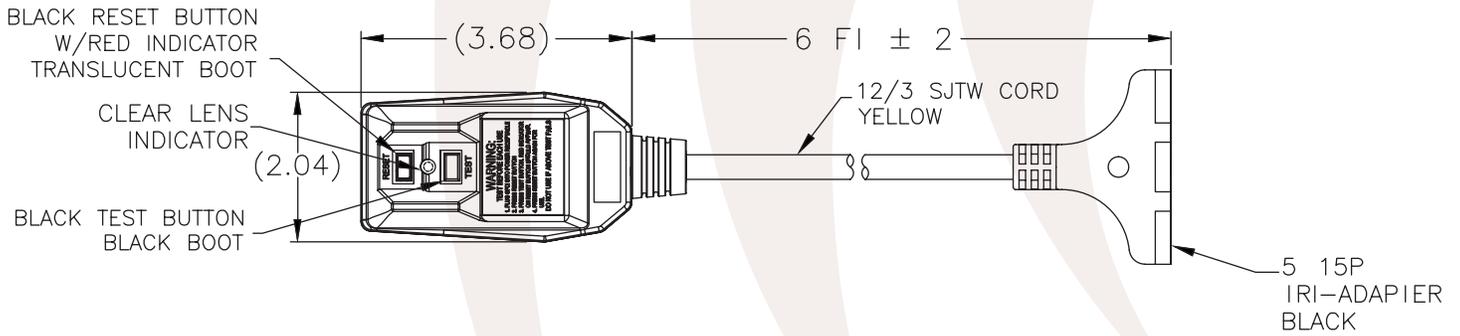


**BUILT FOR DURABILITY.**  
**BUILT FOR RELIABILITY.**  
**BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM


©2023 Southwire Company, LLC. All rights reserved.  
 \*Registered Trademark & ™Trademark of Southwire Company, LLC.



# Southwire™

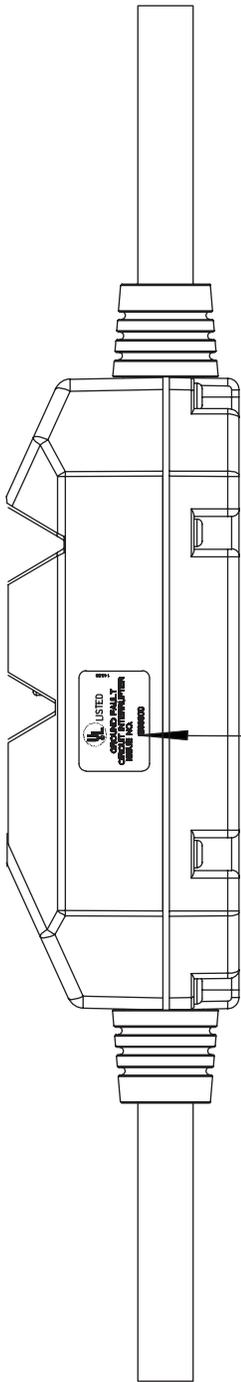

LABEL WHT ON BLACK

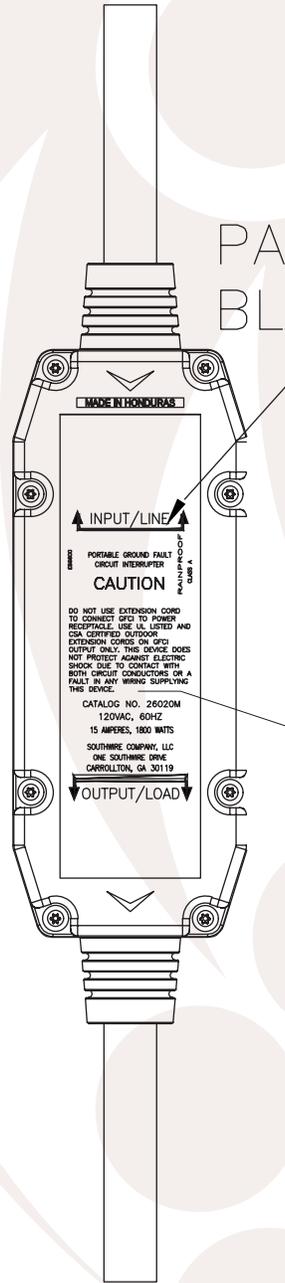

PAD STAMP,  
BLACK

↑ INPUT/LINE ↑

PORTABLE GROUND FAULT  
CIRCUIT INTERRUPTER

**CAUTION**

DO NOT USE EXTENSION CORD  
TO CONNECT GFCI TO POWER  
RECEPTACLE. USE UL LISTED AND  
CSA CERTIFIED OUTDOOR  
EXTENSION CORDS ON GFCI  
OUTPUT ONLY. THIS DEVICE DOES  
NOT PROTECT AGAINST ELECTRIC  
SHOCK DUE TO CONTACT WITH  
BOTH CIRCUIT CONDUCTORS OR A  
FAULT IN ANY WIRING SUPPLYING  
THIS DEVICE.

CATALOG NO. 26020M  
120VAC, 60HZ  
15 AMPERES, 1800 WATTS  
SOUTHWIRE COMPANY, LLC  
ONE SOUTHWIRE DRIVE  
CARROLLTON, GA 30119

↓ OUTPUT/LOAD ↓

RAINPROOF  
CLASS A

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.