



Southwire™

RIGID CONNECTORS

COMPRESSION TYPE - STEEL

FEATURES

- Compression type connector
- Threadless
- Concrete tight

APPLICATION

- Dry location only
- Use to join unthreaded Rigid or IMC conduit to steel outlet box or metal enclosure

STANDARD MATERIAL

- Steel

STANDARD FINISH

- Zinc plated

CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB1-2014



262



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B
261	1/2"	20	200	26	1.35"	1.17"
262	3/4"	10	100	20	1.48"	1.43"
263	1"	5	50	18	1.58"	1.75"
264	1-1/4"	5	50	32	1.86"	2.15"
265TZ	1-1/2"	---	12	11	1.94"	2.38"
266TZ	2"	---	12	14	2.49"	3.38"

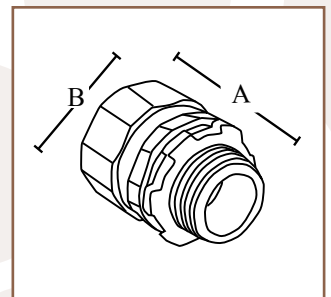

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.