



# Southwire™

## 15A SINGLE OUTLET RIGHT ANGLE ADAPTERS

Provides GFCI and single mode surge protection with any appliance or tool used indoors.



14650013-6

APPLICATIONS
Power Tools
Saws
Drills
Extension Cords
Lighting



**GFCI WITH 4-6MA TRIP POINT**

**25MS TRIP RESPONSE TIME**

**MANUAL RESET**

**PROVIDES COMPLIANCE WITH  
NEC 2008 ARTICLE 590.6 FOR  
TEMPORARY INSTALLATIONS**

**SMALL SIZE (LESS THAN 3" HIGH  
AND 2" WIDE) MAKE IT PERFECT  
FOR THE TOOLBOX**

**APPLICATIONS: INSTITUTIONAL AND  
RESIDENTIAL**

MODEL #	ELECTRICAL RATING			COLOR	RECEPTACLE COUNT
14650006-6	120V	15A	60Hz	White	Single
14650013-6	120V	15A	60Hz	Yellow	Single
14650032-6	120V	15A	60Hz	Black	Single

TECHNICAL DATA	TECHNICAL DATA 2
GROUNDING NEUTRAL	4 Ohms Typical
VOLTAGE SURGE WITHSTAND	3 Kv Ringwave Test and 4Kv/2Ka Surge Immunity Test
RADIO FREQUENCY NOISE SUSCEPTABILITY	Operates Within Normal Limits With 0.5 Volts Injected On Power Line 150Khz-230Mhz
ENDURANCE	3,000 Operations Minimum
OVERLOAD CURRENT	Six Times Rated Current
OPERATING TEMPERATURE RANGE	-35°C to 66°C
EFFECT OF 10 AMP TURN DC SOCK FAULT TRIP	5% Maximum Trip Level Variation on Ground
INSULATION VOLTAGE	1500 Vrms - 1 Min.





**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# Southwire™

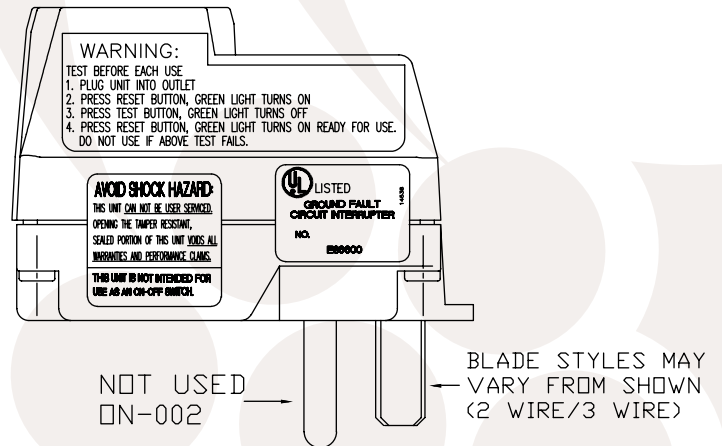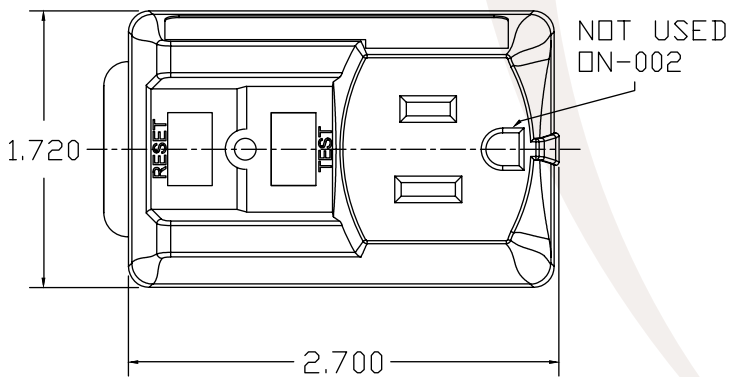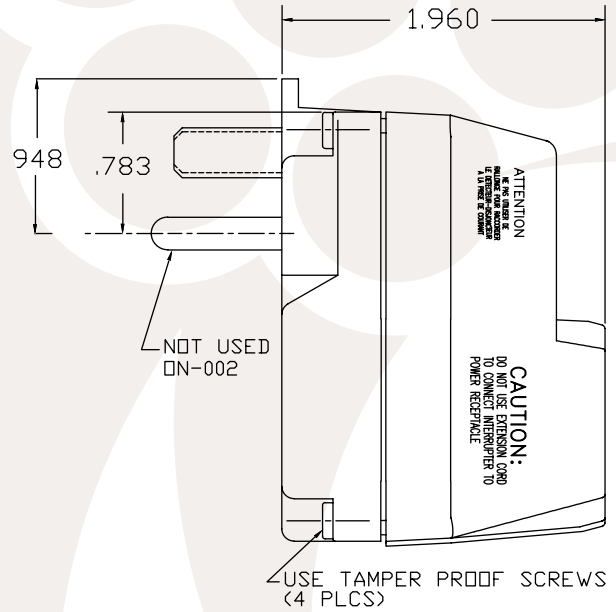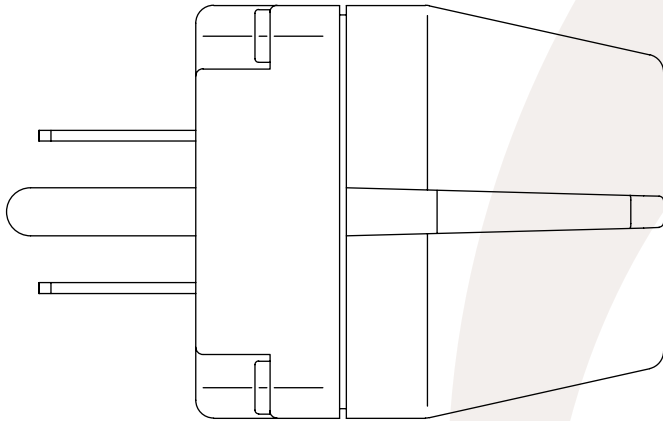

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | [SOUTHWIRE.COM](http://SOUTHWIRE.COM)

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.