



# Southwire™

## EMT AND RIGID COMBINATION CONDUIT BODIES WITH COVER AND GASKET TB TYPE

### FEATURES

- Combination TB type with cover and gasket
- NPT tapered hubs
- Suitable for use in concrete
- NEMA FB 1 rated for wet locations use with threaded rigid metal conduit only

### APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

### STANDARD MATERIAL

- Copper free aluminum die cast
- Cover - Stamped steel
- Gasket - Neoprene rubber

### STANDARD FINISH

- Powder coat

### CERTIFICATIONS


- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



TB1SSCG



PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
TB1SSCG	1/2"	1	6 AWG	10	100	38	5.35"	1.31"	2.02"
TB2SSCG	3/4"	2	6 AWG	10	50	30	6"	1.62"	2.22"
TB3SSCG	1"	3	6 AWG	5	25	18	7.06"	1.88"	2.56"
TB4SSCG	1-1/4"	3	2 AWG	2	10	17	7.25"	2.50"	3.50"
TB5SSCG	1-1/2"	3	2 AWG	2	10	19	9.25"	2.67"	3.50"
TB6SSCG	2"	3	2/0 AWG	---	5	14	11.50"	3.29"	4.25"

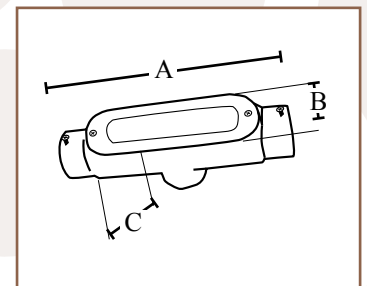

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.