


# MULTICONDUCTOR RISER RATED UNSHIELDED STRANDED BC PVC

## MULTICONDUCTOR RISER RATED UNSHIELDED STRANDED BC PVC



WE'VE GOT IT  
MADE IN AMERICA™

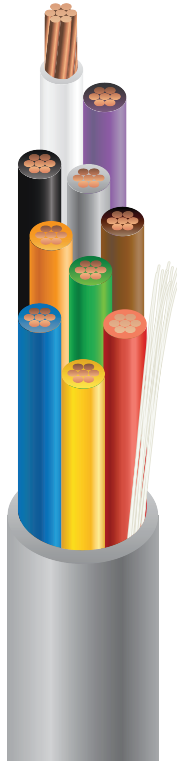

75°C, 300V RISER RATED

### APPLICATION

Remote Control, Signalling, and Power-Limited circuits per NEC Article 725. 22AWG - 6 AWG also as communication circuits per NEC Article 800. Security, sound and audio, speaker cable, public address, intercom, sound reinforcement, alarm and access control circuits and power-limited controls.

### CONSTRUCTION

- CONDUCTOR Stranded or solid bare copper as indicated on on individual product specifications.
- INSULATION PVC
- SHIELDING Unshielded
- ASSEMBLY Cabled, with ripcord, and jacketed.
- JACKET PVC

### SPECIFICATIONS

- UL 444 CMR, NEC article 800
- UL 1424 FPLR, NEC article 760
- UL 13 CL3R, NEC article 725
- Flame Test UL 1666 Vertical Riser / CSA FT4 (UL 1581)
- CSA C22.2 CMG by C(UL)
- Directive (EU) 2015 / 863 – RoHS 3

MULTICONDUCTOR

TYPE	PRODUCT BASE #	DESCRIPTION	RATING	UL TYPE	SHIELDING	CONDUCTOR TYPE	CB NOM DIA MIL	CB LBS/ MFT
MULTICONDUCTOR RISER RATED UNSHIELDED STRANDED BC PVC	R20004	SY 22/2 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	120	8.452
	R20025	SY 22/8 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	181	26.42
	R20045	SY 22/4 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	149	15.66
	R20047	SY 22/6 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	157	20.31
	R20051	SY 22/10 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	194	32.02
	R20487	SY 22/12 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	225	38.88
	R30017	SY 20/2 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	132	11.34
	R40001	SY 18/2 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4 MSHA 300V	RISER	NOT SHIELDED	STRANDED	144	14.82
	R40015	SY 18/6 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	212	41.09
	R40018	SY 18/2 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	144	14.83
	R40024	SY 18/12 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	271	75.76
	R40048	SY 18/3 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	153	20.79
	R40049	SY 18/4 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	166	28.80
	R40052	SY 18/8 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	230	53.17
	R40054	SY 18/10 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	262	64.05
	R50003	SY 16/2 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	174	22.08
	R50045	SY 16/4 STR CU N/S CMR/CL3R	CMR/CL3R/FPLR SUN RES CMG FT4	RISER	NOT SHIELDED	STRANDED	212	41.16
	R60012	SY 14/2 STR CU N/S CL3R/FPLR	CL3R/FPLR SUN RES	RISER	NOT SHIELDED	STRANDED	223	35.53
	R60014	SY 14/4 STR CU N/S CL3R/FPLR	CL3R/FPLR SUN RES	RISER	NOT SHIELDED	STRANDED	263	66.41
	R70003	SY 12/2 STR CU N/S CL3R/FPLR	CL3R/FPLR SUN RES	RISER	NOT SHIELDED	STRANDED	266	52.45