

LED Red Exit & Emergency Combo REMOTE CAPABLE



Essential Illumination

Topaz's Exit and Emergency Combo units offer safety and security in a modern, easy to install design. This fixture is UL, OSHA, NEC and NFPA compliant and contains a long-lasting Ni-Cad battery for essential illumination in the event of a power failure. This exit and emergency fixture is also remote capable, to add two single head remote head lamps, or one double remote head lamp for extra illumination when and where it is needed most.

FEATURES

- Meets NFPA 70, NFPA 101, UL924 NEC / OSHA Standards
- T20: Can be used to comply with California Energy Commission's Lighting Appliance Efficiency Regulations
- Remote capable option to add up to two single or one double remote head lamp
- Battery backup with accessible push to test button for 90 minutes of illumination during a power outage
- Fully adjustable lamp heads - track and swivel for full range adjustability
- Ceiling or wall mount (canopy included)

APPLICATIONS

- Emergency lighting for commercial, industrial, retail and other public spaces
- Stairways and hallways




LED Red Exit & Emergency Combo

REMOTE CAPABLE

GENERAL SPECIFICATIONS

Input Voltage, Frequency: 120/277V, 60Hz
Emergency Duration / Run Time: 90 minutes
Recharge Time: 24 hours
CCT: 5700K
CRI: 80
Recycle Times: 500
Location Rating: Damp
Ambient Operating Temperature: 50°F to 104°F
Lens Type: Polycarbonate
Number of Faces: Single and double
Ceiling or wall mount (canopy included)
Battery Type: (2) Ni-cad 3.6V 900mAh
AC Supply Test Button: Yes
Remote Capabilities: DC 3.6V 1.5W Max

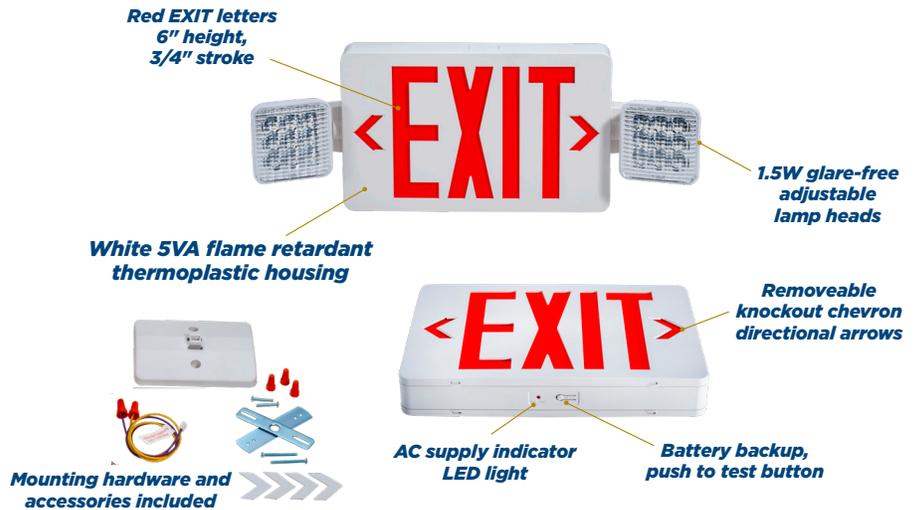


SPECIFICATIONS / ORDER INFO

| Order Catalog Number | Code | UPC | Lumens | Input Wattage | Output Wattage | Input Current @120V/277V | Number of Lamps Heads | CA T20 |
|----------------------|--------------------|--------------|--------|---------------|----------------|--------------------------|-----------------------|--------|
| ESC/LED/RW/RC | 72112 | 751338039254 | 150 | 3.5W | 1.5W | 33/15mA | 2 | Y |
| EL1/LED/WH/RH | 70917 ¹ | 751338037908 | 75 | 0.75W | 0.75W | - | 1 | - |
| EL2/LED/WH/RH | 70918 ¹ | 751338037922 | 150 | 1.5W | 1.5W | - | 2 | - |

¹ Not for sale in California.


NOMENCLATURE

ESC = Emergency Lighting Combo / **LED** = LED / **RW** = Red Letters, White Housing / **RC** = Remote Capable
EL1 = Emergency Lighting 1 Head / **LED** = LED / **WH** = White Housing / **RH** = Remote Head
EL2 = Emergency Lighting 2 Head

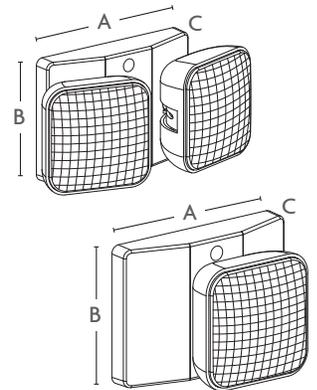


PRODUCT DIMENSIONS / LINE DRAWING

| Catalog Number | (A) | (B) | (C) | Weight |
|----------------|--------|-------|-------|-----------|
| ESC/LED/RW/RC | 19.09" | 7.28" | 3.7" | 2.86 Lbs. |
| EL1/LED/WH/RH | 6.0" | 4.25" | 3.5" | 0.44 Lbs. |
| EL2/LED/WH/RH | 6.0" | 4.25" | 3.38" | 0.66 Lbs. |

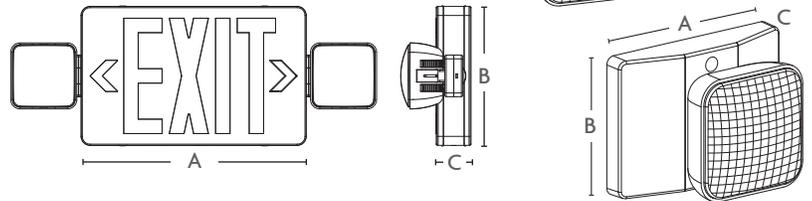

SPACING GUIDELINES

| Catalog Number | Mounting Height | Center To Center Spacing | Path of Egress |
|----------------|-----------------|--------------------------|----------------|
| ESC/LED/RW/RC | 7.5' | 18' | 6' |
| | 10' | 17' | 6' |
| EL1/LED/WH/RH | 7.5' | 11' | 6' |
| | 10' | 9' | 6' |
| EL2/LED/WH/RH | 7.5' | 20' | 6' |
| | 10' | 18' | 6' |

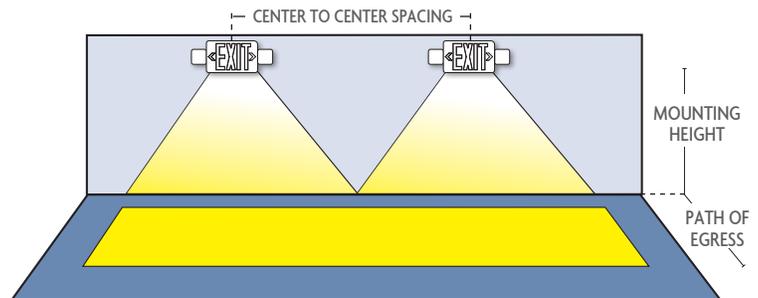

Compliant NFPA 101 requires 1.0 foot-candle average and 0.1 footcandle minimum with a 40:1 maximum/minimum ratio.

NOTES:

Specifications subject to change without prior notice. Replacement wattage shown depends on application and fixture.
 This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

WARNING: Some products included in this specification sheet may be subject to the warning requirements of California's Proposition 65. Please refer to your product packaging for more information.

March 2021