



Southwire™

RIGID CONDUIT BODIES

THREADED C TYPE

FEATURES

- Threaded C type
- NPT tapered hubs
- Suitable for use in concrete
- Suitable for use in wet locations

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



C1TZ

PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
C1TZ	1/2"	1	6 AWG	10	100	24	4.72"	1.370"	1.33"
C2TZ	3/4"	2	6 AWG	10	50	21	5.57"	1.625"	1.54"
C3TZ	1"	3	6 AWG	5	25	15	6.46"	1.90"	1.74"
C4TZ	1-1/4"	3	2 AWG	2	10	15	8.528"	2.77"	2.49"
C5TZ	1-1/2"	3	2 AWG	2	10	9	8.528"	2.77"	2.49"
C6RTZ	2"	3	2/0 AWG	1	5	13	10.831"	3.335"	3.10"
C7	2-1/2"	3	4/0 AWG	---	1	3	13.50"	4.06"	4.45"
C8	3"	3	250 MCM	---	1	6	13"	4.685"	4.45"
C9	3-1/2"	3	350 MCM	---	1	8	15.937"	5.45"	5.50"
C10	4"	4	350 MCM	---	1	8	15.937"	5.45"	5.50"

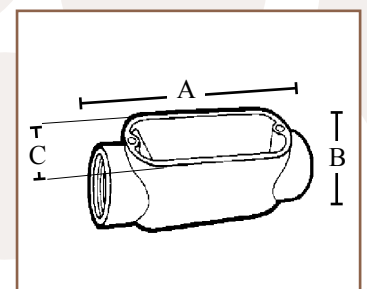

Rev. 0, 05/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.