



# Southwire™

## RIGID LOCKNUTS

### UL LISTED - STEEL

#### FEATURES

- Tightens without deformation
- UL listed

#### APPLICATIONS

- To connect externally threaded conduit or connector to a threadless opening in a box or enclosure

#### STANDARD MATERIAL

- Steel

#### STANDARD FINISH

- Zinc plated

#### CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB1-2014



281UL



PART #	SIZE	THREADS PER INCH	INNER QTY.	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B	THREAD PITCH DIAMETER
281UL	1/2"	14	200	2000	23	1.15"	.125"	.787 – .797
282UL	3/4"	14	100	1000	23	1.45"	.14"	.999 – 1.009
283UL	1"	11-1/2	100	1000	33	1.75"	.1875"	1.250 – 1.260
284UL	1-1/4"	11-1/2	50	500	23	2.10"	.1875"	1.595 – 1.605
285UL	1-1/2"	11-1/2	50	500	33	2.40"	.1875"	1.837 – 1.847
286UL	2"	11-1/2	25	250	23	2.95"	.1875"	2.307 – 2.317
287UL	2-1/2"	8	---	50	8	3.55"	.215"	2.777 – 2.788
288UL	3"	8	---	50	12	3.55"	.215"	3.403 – 3.414
289UL	3-1/2"	8	---	25	9	4.20"	.215"	3.892 – 3.904
290UL	4"	8	---	25	10	4.75"	.215"	4.399 – 4.411

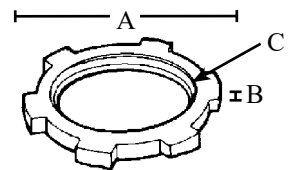

Rev. 0, 05/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.