



# Southwire™

## 30A 120V IN-LINE CORD SETS

Shockshield in-line GFCI ensures protection from dangerous current leakage that can cause electrical shock and possible electrocution.



**44830004-3**

APPLICATIONS
High Pressure Sprayer Washers
Construction Site Power Tools
Drain Snakes
Pumps
Construction Sites
Industrial Appliances

**GFCI WITH 4-6MA TRIP POINT**

**25MS TRIP RESPONSE TIME**

**MANUAL RESET**

**PROVIDES COMPLIANCE WITH  
NEC 2008 ARTICLE 590.6 FOR  
TEMPORARY INSTALLATIONS**

**CUSTOM CABLE GAUGES, LENGTHS  
AND TERMINATIONS AVAILABLE BY  
SPECIAL ORDER**

**APPLICATIONS: PLANT  
MAINTENANCE, EQUIPMENT  
SERVICE AND CONSTRUCTION SITES**

MODEL #	ELECTRICAL RATING			CORD LENGTH	CORD GAUGE	WIRE TYPE	COLOR	RECEPTACLE COUNT	LIGHTED RECEPTACLE
44830004-3	120V	30A	60Hz	2'	10/3 AWG	SJ00W	YELLOW	SINGLE	NO
44830005-2	120V	30A	60Hz	6'	10/3 AWG	SJ00W	YELLOW	SINGLE	NO

TECHNICAL DATA	
GROUNDING NEUTRAL	4 Ohms Typical
VOLTAGE SURGE WITHSTAND	3 Kv Ringwave Test and 4Kv/2Ka Surge Immunity Test
RADIO FREQUENCY NOISE SUSCEPTABILITY	Operates Within Normal Limits With 0.5 Volts Injected On Power Line 150Khz-230Mhz
ENDURANCE	3,000 Operations Minimum
OVERLOAD CURRENT	Six Times Rated Current
OPERATING TEMPERATURE RANGE	-35°C to 66°C
EFFECT OF 10 AMP TURN DC SOCK FAULT TRIP	5% Maximum Trip Level Variation on Ground
INSULATION VOLTAGE	1500 Vrms - 1 Min.
POWER INDICATION	Lighted Indicator





**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**1-855-798-6657 | SOUTHWIRE.COM**

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# Southwire™

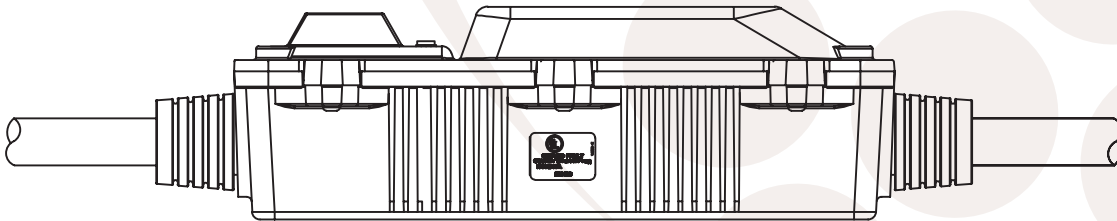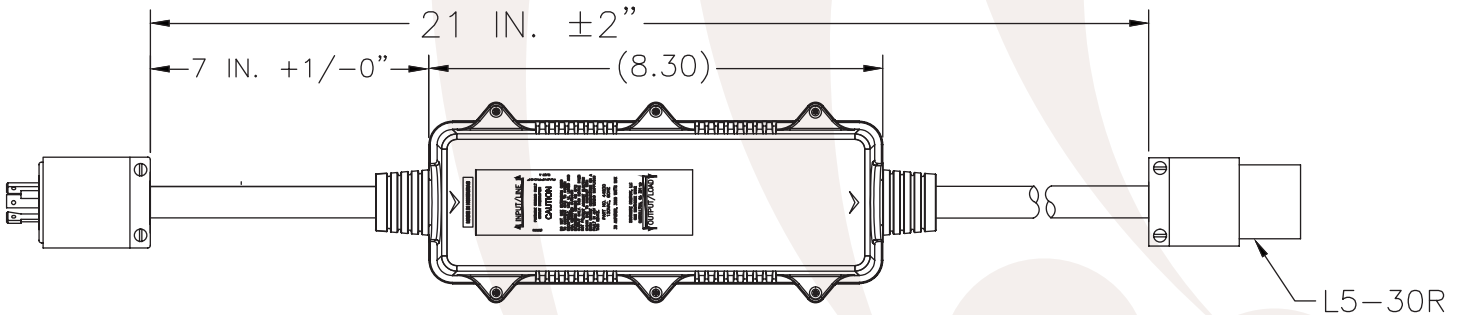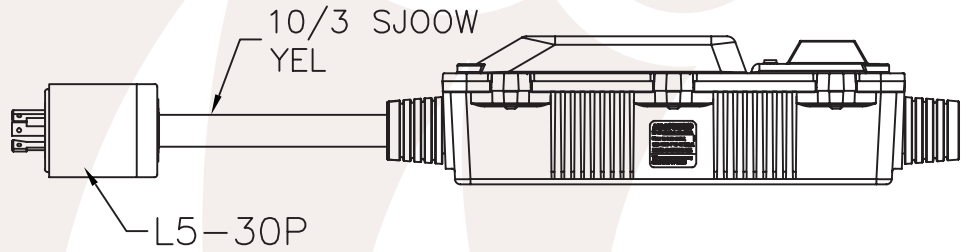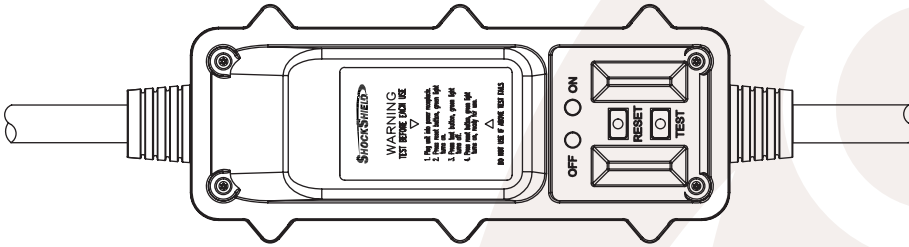

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.