



LED PAR HIGH-POWER

SUGGESTED APPLICATIONS

- Ideal for track lighting, recessed lighting, pendant lighting, residential and hospitality

FEATURES

- Dimmable down to 5% of total light output
- Advanced optics & thermal management
- Suitable for use in enclosed fixtures

INPUT VOLTAGE: 120V

FREQUENCY: 50/60Hz

BASE: E26

**LENS TYPE:
SHATTER-RESISTANT PLASTIC**

**LIFETIME (L70):
UP TO 25,000 HOURS**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED PAR HIGH-POWER

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	LUMENS PER WATT	BEAM ANGLE	CCT	CRI	INPUT AMPS
LP16/6/27K/D-46	79676	751338005266	500	6.5W	77	40°	2700K	80	54mA
LP16/6/30K/D-46	79677	751338005273	500	6.5W	77	40°	3000K	80	54mA
LP16/6/40K/D-46	79678	751338005280	500	6.5W	77	40°	4000K	80	54mA
LP16/6/50K/D-46	79679	751338005297	500	6.5W	77	40°	5000K	80	54mA

ORDERING GUIDE

Example: LP16/6/50K/D-46


PRODUCT	WATTAGE	CRI	OPTIONS
LP = LED PAR 16 Shape	6 = 6 Watts	50K = 5000K	D = Dimmable

ENERGY SAVINGS Based on 6 hours/day and \$0.11/kWh

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LP16/6/50K/D-46	6.5W	60W	53.5W	\$12.89	\$64.45

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
LP16/6/xxK/D-46	2.85	2.4	.1

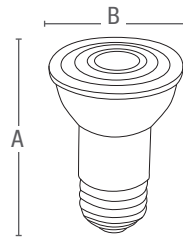

NOTES

Not for sale in California.

*Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 5%). Product performance may vary depending on dimmer manufacturer and circuit loading. Visit www.southwire.com or contact your local Southwire representative for a list of compatible dimmers.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. Specifications subject to change without notice.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC: For details visit: <https://southwire.com/resources/warranties>

Specifications subject to change without notice.



800-666-2852 | SOUTHWIRE.COM

©2025 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.