



LED SURFACE MOUNT DOWNLIGHT

CCT SELECTABLE WITH MOTION SENSOR

SUGGESTED APPLICATIONS


- Commercial and residential
- Multi-family, hospitality, hallways, living rooms
- Surface mount installations in most 3-1/2" and 4" junction boxes
- Retrofit installations for 5/8" recessed can housings
- Suitable for use in clothes closets when installed in accordance with NFPA 70, NEC section 410.16 (A)(3) and 410.16 (C)(5)

FEATURES

- ENERGY STAR® Certified, highly energy efficient
- Sleek, ultra-thin profile surface mount downlight
- 5 CCT Selectable: 2700K, 3000K, 3500K, 4000K or 5000K
- Motion sensor switch settings:
 - Single level
 - Bi-level
 - Off/Motion sensor disabled
- Excellent 90 CRI light with uniform wide beam distribution
- Flicker free dimming down to 10%
- Torsion springs and E26 base adapter accessories included for retrofit mounting



Motion sensor and CCT selectable switches

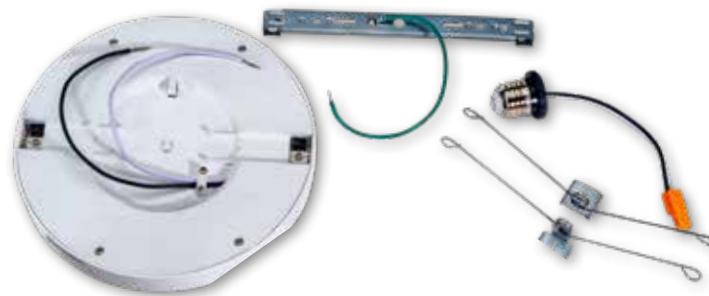

INPUT VOLTAGE: 120V

FREQUENCY: 60Hz

POWER FACTOR: >0.9, <30%

**DIMMABLE: LINE VOLTAGE
DOWN TO 10%¹**

EFFICACY: 88 LPW

CRI: 90

BEAM ANGLE: 110°

LIFETIME (L70): 50,000 HOURS

LOCATION RATING: DAMP

**AMBIENT OPERATING
TEMPERATURE: -13°F TO 104°F**

**CONSTRUCTION: ALUMINUM
HOUSING WITH WHITE,
BRONZE OR BRUSHED NICKEL
FINISH, SMOOTH FRAME AND
POLYCARBONATE LENS**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED SURFACE MOUNT DOWNLIGHT

CCT SELECTABLE WITH MOTION SENSOR

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	INPUT CURRENT	CCT	T24 JA8	ENERGY STAR
SMD7/RND/13/CTS/MS	71018	751338039049	1,150	13W	110mA	2700K 3000K 3500K 4000K 5000K	Y	Y

ORDERING GUIDE

Example: **SMD7/RND/13/CTS/MS**


PRODUCT	SIZE	SHAPE	WATTAGE	CCT	OPTIONS
SMD = SURFACE MOUNT DOWNLIGHT	7 = 7"	RND = ROUND	13 = 13 WATTS	CTS = COLOR TEMPERATURE SELECTABLE	MS = MOTION SENSOR

ENERGY SAVINGS *Based on 12 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
SMD7/RND/13/CTS/MS	13W	75W	62W	\$29	\$149

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
SMD7/RND/13/CTS/MS	8.19	0.89	0.9

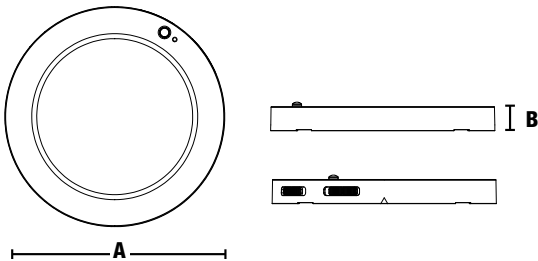

MOTION SENSOR SWITCH SETTINGS

SETTING	MOTION DETECTED	MOTION NOT DETECTED FOR 3 MINUTES
Single level	Full on*	Full off
Bi-level	Full on*	20% light output
Off/Disabled	Fixture controlled exclusively by the wall switch when motion sensor is disabled	

* Fixture will illuminate no greater than the level selected by a dimmer when dimming functionality is used

NOTES

¹Dimming- This product is designed to be compatible with most leading-edge type incandescent and LED style dimmers. (Dimming range 100% down to 10%). Product performance may vary depending on dimmer manufacturer and circuit loading. Contact your local Southwire representative for a list of compatible dimmers.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.



800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.