



# Southwire™

## SIMpull™ NON-CONDUCTIVE FISH TAPE

### NON CONDUCTIVE

Our safest option for installation over existing wires

### TAPERED TIP

Reduces the likelihood of snagging on wires & conduit when reeling-in the fish tape

### LASER ETCHED FOOT MARKINGS

Identify conduit run lengths with incremental foot markings

### IMPROVED PUSH

5.5mm tape works well in conduit up to 3 inches  
4.5mm tape works well in conduit up to 2 inches

### ADVANCED TAPE GUIDE


Improved housing mechanics for smoother payout & reel-in

### IMPACT RESISTANT CASE

Certified Drop Rating of 15 Feet



SCAN TO SEE MORE

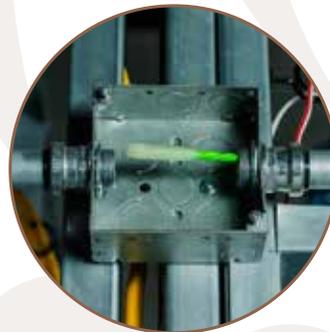

MODEL #	STOCK #	UPC #	DESCRIPTION	HEIGHT	WIDTH	DEPTH	WEIGHT
FTSP55-125NCT	67015540	032886751219	SIMpull™ Non-Conductive Tip 5.5mm 125'	16"	12"	2"	2.5 lbs
FTSP45-125NCT	63163740	032886964657	SIMpull™ Non-Conductive Tip 4.5mm 125'	16"	12"	2"	2.5 lbs
FTSP45-75NCT	63029840	032886963148	SIMpull™ Non-Conductive Tip 4.5mm 75'	16"	12"	1.5"	2.0 lbs
FTSP4.5FML-LRKIT	64277640	032886985942	SIMpull™ Replacement Leader Kit, 2x of each Leader Included 4.5mm	6"	17"	4"	2.6 lbs
FTSP3.0FML-LRKIT	64277940	032886985966	SIMpull™ Replacement Leader Kit, 2x of each Leader Included 3.0mm	6"	17"	4"	2.6 lbs

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2021 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.