


Pipe connector with tongue, complete, to pipe 2" Schedule 80
 Part no. D2744-02

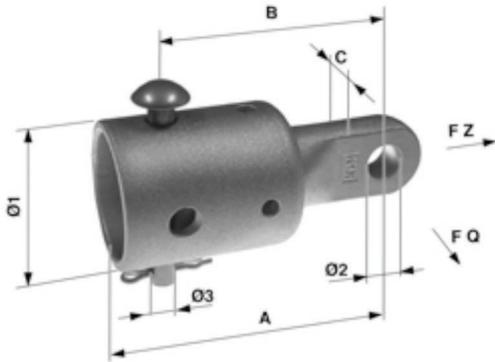

Technical data

Dimensions

A: 140 mm
 B: 115 mm
 C: 18 mm
 Ø1: 48.0 mm
 Ø2: 17 mm
 Ø3: 12 mm

Material and weight

Material: Al/SST

Loads and tightening torque

Breaking load F across: 15 kN
 Breaking load F on traction: 38 kN

Standards applied

-

Function

-

Specifications

-

Spare parts

Tongue, with thread M16, Part no. D2357-01
 Pin, 12 x 80, Part no. E3232-03
 Cotter pin, 4.0 x 30, Part no. E3234-01

Accessories

-

Comments

- The pipe connector G2" and additionally the distance bushing part no. E 3259-01 must be used for pipe G2.5" w/reinforced wall
 - Other pole diameter on request



Southwire™



A COLAS RAIL COMPANY

Contact Us: Transit@southwire.com