



**Southwire™**

# CABLE/CONDUIT SUPPORT MC, NM TO STUD WALL

## APPLICATION

Easily installs to secure NM or MC cables to wood or metal studs. Designed with a flared edge for maximum cable protection.

## FEATURES


Supports up to 6 runs of NM sheathed cable or 4 runs of MC and AC cables  
Collapsible leg locks and secures cables for a snug fit  
Locating ribs to maintain cable separation

## MATERIAL/FINISH


Steel/Zinc Plated

## CERTIFICATIONS

UL Standard: UL 2239  
NEC® 300.4D applicable

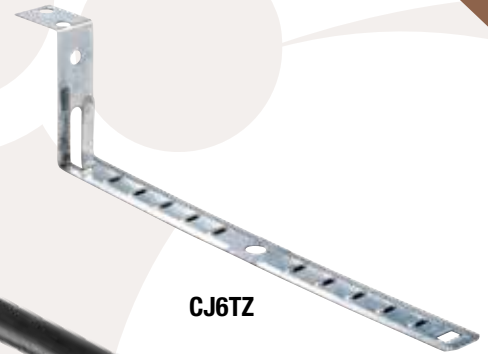

CJ6TZ

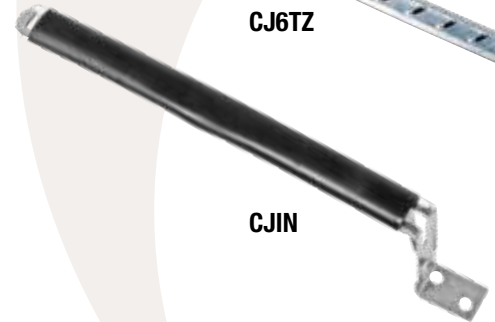

CJIN



PART #	CABLE SURFACE	LENGTH	BOX QTY.
CJ6TZ	STEEL	6"	100
CJIN	INSULATED RUBBER	6"	100

STUD TYPE	CABLE TYPE	CABLE SIZE	CABLES PER FASTENER
Wood	Non-Metallic	14-2, 12-2, 10-2, 14-3, 12-3, AND 10-3 WITH GROUND	Max 6
		8 -2 AND 6-2 WITH GROUND	Max 4
Metal Stud	Metal Clad (MC)	14-2, 12-2, 10-2, 14-3, 12-3, 10-3, 14-4, 12-4, AND 10-4 WITH GROUND	Max 4

Rev. 0, 01/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.