



Southwire™

BX, FLEX CONNECTORS

STRAIGHT - SQUEEZE TYPE - MALLEABLE IRON

FEATURES

- Squeeze type straight

APPLICATION

- Indoor use only
- In a dry location, use to connect flexible metallic conduit and steel AC cable to a steel outlet box, load center or other metal enclosure
- The 3/8" can also be used with steel and aluminum MC cable
- 3/8" size fits 1/2" knockout
- Suitable for: 3/8" steel flexible conduit, #14-2 metal conduit and #4-2 wire steel armored cable, 3/4" steel flexible metal conduit and #6-3 wire steel armored cable, 1" steel and reduced wall steel flexible metal conduit and #2-2 wire steel armored cable and 1-1/4" - 4" steel flexible metal conduit

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH

- Zinc plated


CERTIFICATIONS

- cULus



151M

PART #	CONDUIT SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B (MIN. – MAX.)	C	SCREWS
150M	3/8" 1/2"KO	25	250	30	.93"	.55" – .60"	.50"	1
151M	1/2"	25	250	30	.94"	.78" – .94"	.50"	1
152M	3/4"	25	250	48	1.13"	.91" – 1.08"	.50"	1
153M	1"	10	100	26	1.19"	1.28" – 1.44"	.56"	1
154M	1-1/4"	10	100	39	1.25"	1.44" – 1.63"	.63"	1
155M	1-1/2"	5	50	33	1.88"	1.63" – 1.88"	.69"	1
156M	2"	---	20	21	2"	2.19" – 2.38"	.75"	1
157M	2-1/2"	---	10	14	2.06"	2.70" – 2.95"	.94"	2
158M	3"	---	2	4	2.25"	3.13" – 3.50"	.94"	2
159M	3-1/2"	---	1	5	3.56"	3.72" – 4"	1.25"	2
160M	4"	---	1	7	3.69"	4.06" – 4.44"	1.25"	2

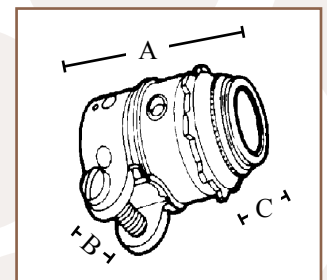

Rev. 0, 05/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.