


# Mini Split Cable

## Spinalcord Metal Clad

# -GENESIS-

Genesis Metal Clad Mini Split Cables deliver versatility to accommodate indoor and outdoor installations with or without conduit. Their lightweight aluminum cladding, direct burial, and sunlight resistant features enable them to withstand harsh and wet environments.

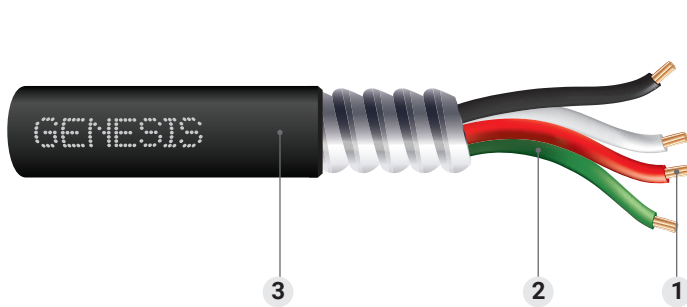

### Construction

- 1. Conductor:** Bare Copper conductors for excellent conductivity and low voltage drop
- 2. Insulation:** THHN
- 3. Jacket:** Metal Cladded with PVC

### Applications

Installed in-wall in one- and two-family dwelling units

In burial applications

### Specifications

UL 1569 Metal-Clad Cables

Direct Burial Rated

Sunlight Resistant Rated








Oil Resistant I Rated

REACH/RoHS Compliant

Rated for 600 Volts

Rated for -20°C to 90°C Dry/75°C Wet

### Conductor Color Codes: Mini Split Cable

Conductor Number	Color
1	Black 
2	White 
3	Red 
4	Green 
5	Brown 
6	Blue 
7	Orange 

### Sample Print Legend

GENESIS P/N 1075 – SPINALCORD™ MINI SPLIT CABLE 14 AWG 4C THHN/THWN E189204  
(UL) TYPE MC 600V DIR BUR SUN RES OIL RES I (RoHS) W/O# DD/MM/YYYY

Mini Split Cable, Metal Clad

Part Number	Conductor Size (AWG)	Number of Conductors	Stranding	Insulation Thickness (in)	Jacket Thickness (in)	Nominal Diameter (in)	DC Resistance (Ohms/1000ft at 20°C)	Weight (lbs/1000ft)
1075	14	4	7-strand	0.015	0.050	0.574	2.62	163.1

**Genesis Cable**  
7701 95th Street  
Pleasant Prairie, WI 53158  
Office: 800.222.0060  
[www.genescable.com](http://www.genescable.com)



**-GENESIS-**