



Southwire™

RIGID CONDUIT BUSHINGS

MALLEABLE IRON

FEATURES

- Rounded surface of the bushing prevents damage to wire insulation

APPLICATION

- Indoor or outdoor use
- Use with locknut to terminate threaded Rigid or IMC conduit to an outlet box

STANDARD MATERIAL


- Malleable iron



301M



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
301M	1/2"	100	1000	50	1.223"	.48"
302M	3/4"	50	500	30	1.498"	.49"
303M	1"	25	250	24	1.818"	.56"
304M	1-1/4"	25	250	30	2.423"	.61"
305M	1-1/2"	---	25	22	2.512"	.68"
306M	2"	---	25	35	3.053"	.68"
307M	2-1/2"	---	15	20	3.624"	.85"
308M	3"	---	10	10	4.172"	.91"
309M	3-1/2"	---	10	13	4.767"	1"
310M	4"	---	10	20	5.321"	1.06"
310AM	5"	---	10	25	6.15"	1.30"
310BM	6"	---	10	35	7.19"	1.30"

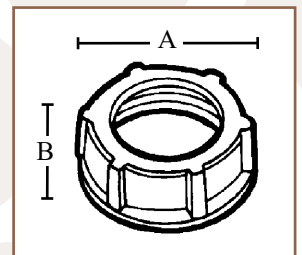

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.