

Items:  
 F-CPS/40W/40K/BZ-87  
 F-CPS/40W/50K/BZ-87  
 F-CPS/60W/40K/BZ-87  
 F-CPS/60W/50K/BZ-87



## CANOPY LUMINAIRE INSTALLATION INSTRUCTIONS



Read instructions carefully before installing. Keep these instructions for future reference. Topaz fixtures must be wired in accordance with the National Electrical Code and all applicable local codes. Proper grounding is required for safety. **THIS PRODUCT MUST BE INSTALLED IN ACCORDANCE WITH THE APPLICABLE INSTALLATION CODES BY A QUALIFIED ELECTRICIAN WHO IS FAMILIAR WITH THE CONSTRUCTION AND OPERATION OF THE PRODUCT AND THE HAZARDS INVOLVED.**

Part No.	Input Voltage	Frequency	Power	Rated Current
F-CPS/40W/40K/BZ-87	120-277VAC	50/60Hz	40W	0.367A/0.159A 120V/270V
F-CPS/40W/50K/BZ-87	120-277VAC	50/60Hz	40W	
F-CPS/60W/40K/BZ-87	120-277VAC	50/60Hz	40W	0.550A/0.240A 120V/270V
F-CPS/60W/50K/BZ-87	120-277VAC	50/60Hz	40W	

### CAUTIONS

1. Be certain electrical power is OFF before and during installation and maintenance.
2. To prevent wiring damage or abrasion, do not expose wiring to edges of sheet metal or other sharp objects.
3. Do not use the LED Canopy Light near heating appliances/ elements.
4. LED Canopy Light must operate with an ambient temperature range of -40 °C (-40°F) and 40 °C (104°F).
5. LED Canopy Light is not intended for use with emergency exits.

### Wiring Diagram

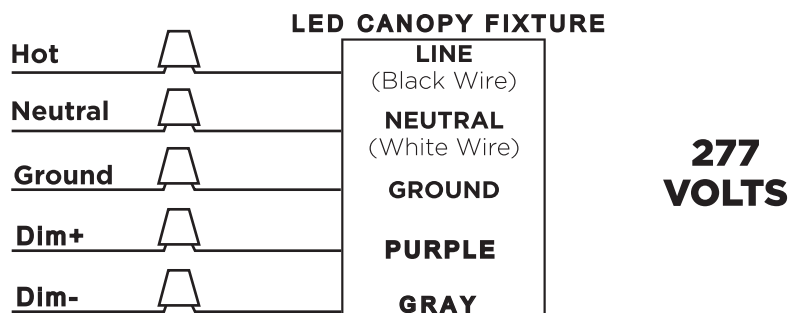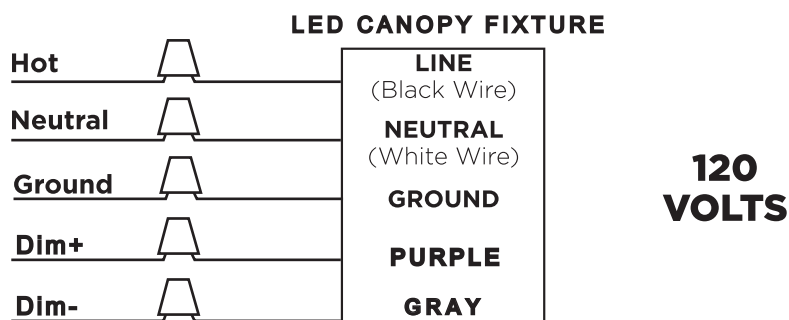

Wiring diagrams available on page 3 for other voltage options.  
 Please cap the gray and purple wires separately when not using the dimming feature.

Items:  
 F-CPS/40W/40K/BZ-87  
 F-CPS/40W/50K/BZ-87  
 F-CPS/60W/40K/BZ-87  
 F-CPS/60W/50K/BZ-87




## CANOPY LUMINAIRE INSTALLATION INSTRUCTIONS


### Installation Instruction

#### Installation method I : Ceiling Installation


1. Loosen the screw to take off the mounting plate from fixture.

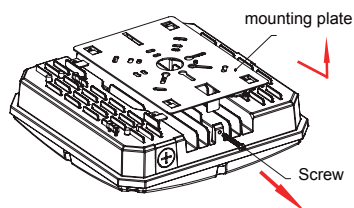


2. Use screws to lock the mounting plate onto the junction box.

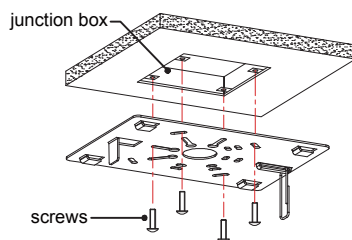


3. Hang the fixture on the ring clip and connect wires with wire caps according to the wiring diagram.

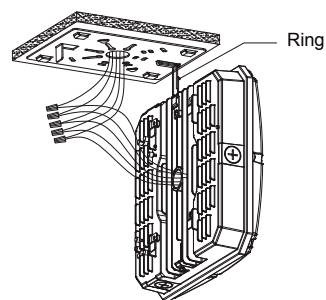

4. Hook fixture on to the mounting plate.

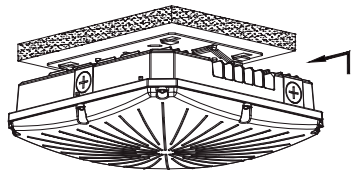


5. Fasten the screw. Installation is complete.

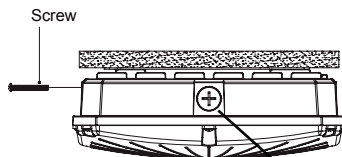


(3) 1/2" knockouts on sides for optional accessories.

#### Installation method II: Pole-pendant Installation

1. Connect wires with wire caps according to the wiring diagram.

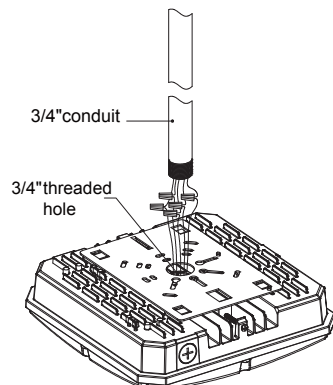

2. Adjust conduit accordingly. Installation is complete.

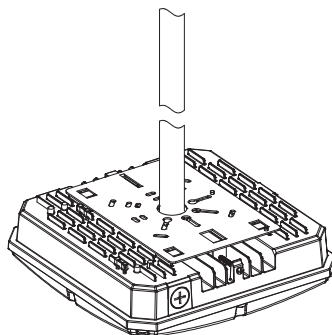




Friendly Service ... Powerful Solutions™

## CANOPY LUMINAIRE INSTALLATION INSTRUCTIONS

### Items:

F-CPS/40W/40K/BZ-87    F-CPS/40W/50K/BZ-87  
F-CPS/60W/40K/BZ-87    F-CPS/60W/50K/BZ-87


### LED CANOPY FIXTURE

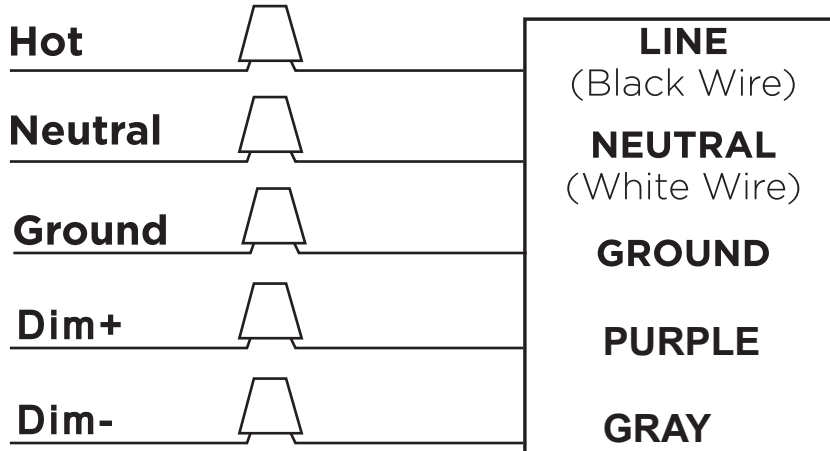

**208  
VOLTS**

**208V Split Phase  
Wiring (USA 3 Wire)**

### LED CANOPY FIXTURE

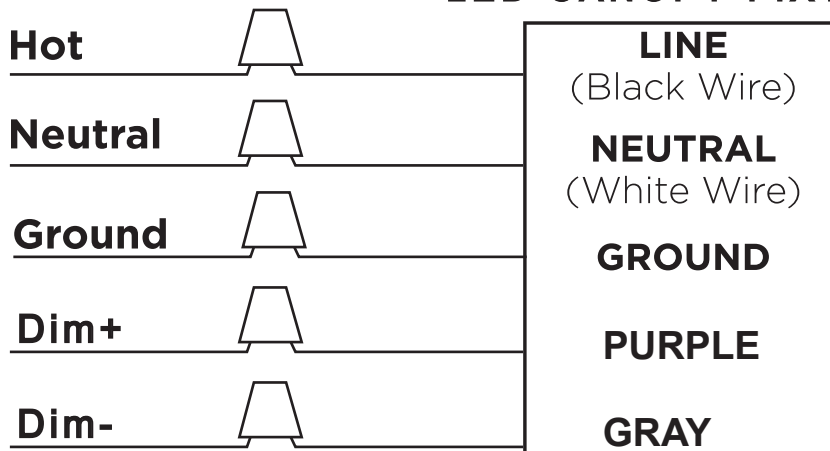

**240  
VOLTS**

**240VAC Split Phase  
Wiring (USA 3 Wire)**

**Please cap the gray and purple wires separately when not using the dimming feature.**