



LED LINEAR WRAP

MODERN - WIDE BODY

SUGGESTED APPLICATIONS

- Commercial, residential
- New construction or remodel
- Offices, schools, retail, general task lighting
- Suitable for use in closets: Compliant with NFPA 70 NEC section 410.16 (A)(3) and 410.16 (C)(5)

FEATURES

- 10" wide body is the perfect solution for retrofit applications providing full coverage from old fixture
- Side ½" knockouts allow easy access connection for wire and conduit
- Smooth 0-10V dimming, down to 10%
- Sleek modern white steel housing with frosted polycarbonate lens
- Surface mount hardware included
- 2' & 4' standard models available with 4000K, 5000K, CCT selectable, and emergency battery backup options

INPUT VOLTAGE: 120-277V

FREQUENCY: 50/60HZ

POWER FACTOR, THD %:
>0.9; <20%

 
DIMMABLE: 0-10V,
DOWN TO 10%

EFFICACY: UP TO 114 LPW

CRI: 80

BEAM ANGLE: 120°

LIFETIME (L70): 50,000 HOURS



BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™

800-666-2852 | TOPAZ-USA.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.

Job Name/Title: _____

Model #: _____

Contractor: _____



TOPAZ®

A Southwire Company

LED LINEAR WRAP MODERN - WIDE BODY

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	SIZE (TRADE)	LUMENS	WATTAGE	INPUT CURRENT @120V/277V"	CCT	DLC ID
LWRAPW4-50-PCS-D	74432	032886308277	4 FT	3,657 4,657 5,689	30W 40W 50W*	0.25/0.11A 0.34/0.15A 0.42/0.19A	3500K 4000K* 5000K	S-MJAWNF / S-01XZ56

*DEFAULT POWER & CCT SELECT SETTING

NOMENCLATURE

Example: LWRAPW4-50-PCS-D

PRODUCT	SIZE	WATTAGE	CCT	OPTIONS
LWRAPW = LINEAR WRAP WIDE BODY	4 FT	P = POWER SELECTABLE 30W/40W/50W	CS = COLOR SELECTABLE	D = DIMMABLE

ACCESSORIES (SOLD SEPARATELY)


MODEL #	ORDER CODE	UPC	DESCRIPTION
LWRAPW-VHK-CHAIN	74420	032886308536	41" V-Hook and chain
BEL4W-UNV	72764	---	LED Emergency Driver
WD-OS	72700	751338004931	Occupancy Sensor

ENERGY SAVINGS *Based on 12 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	FLUORESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LWRAPW4-50-PCS-D	30W	2x 32W T8 LBF	12W	\$6	\$29
LWRAPW4-50-PCS-D	40W	2x 32W T8	20W	\$10	\$48
LWRAPW4-50-PCS-D	50W	2x 32W T8 HBF	19W	\$9	\$46

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	C (IN)	WEIGHT (LBS)
LWRAPW4-50-PCS-D	47	9.8	2.4	6.2

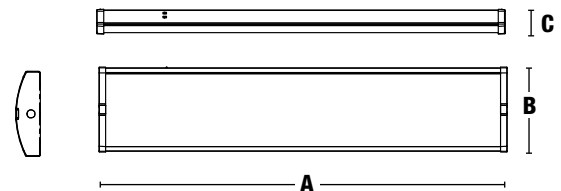

NOTES

DLC Primary Use Direct Linear Ambient Luminaires/Stairwell and Passageway Luminaires

Dimming with standard 0-10V control system or wall dimmers. Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Dimming performance may vary based on selected dimmer.

Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.