



Southwire™

TOOLS & EQUIPMENT


SIMpull HEAD® PULLING DEVICE

Available in sizes from 8 AWG to 1000 AWG the SIMpull Head® eliminates the need to make up a pulling head on the job site and reduces waste.

PATENTED GRIPPING SYSTEM

**SAVES TIME MAKING
PULLING HEADS**

**AVAILABLE IN
STAGGERED LENGTHS**

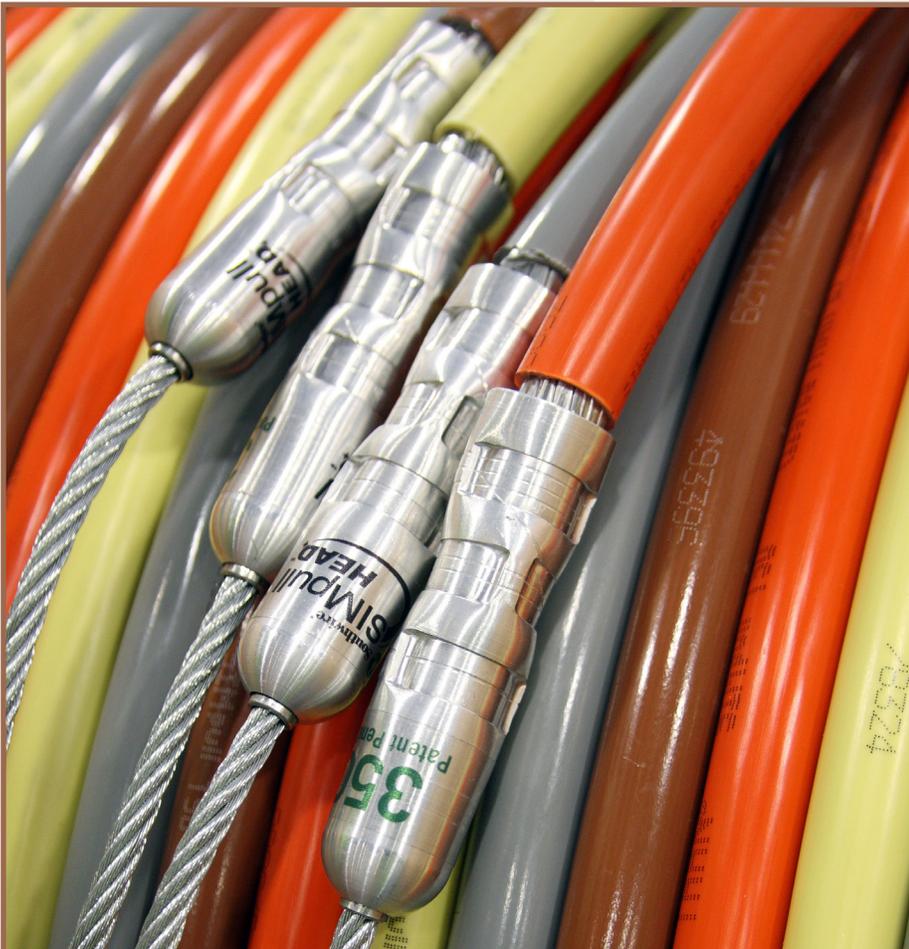

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



SIMpull HEAD® PULLING DEVICE

FEATURES & BENEFITS

- Factory and Field installable pulling grip
- Eliminates the need to make up a pulling head on the job site and reduces waste.
- Low profile head eliminates the problem of the head not fitting in the conduit or around a tight turn
- Saves time making pulling heads
- Patented gripping system – factory installed conductors guaranteed not to pull loose during your pull
- Available in 6", 12", 18", 24", & 30" Staggered lengths

SPECIFICATIONS

8 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
6 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
4 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
3 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
2 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
1 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
1/0 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
2/0 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
3/0 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
4/0 AWG SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
250 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
300 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
350 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
400 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
500 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
600 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
700 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
750 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 6", 12", 18", 24", & 30" Staggered lengths
900 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 9", 15", 21", 27", & 33" Staggered lengths
1000 KCMIL SIMpull HEAD® PULLING DEVICE	Available in 9", 15", 21", 27", & 33" Staggered lengths

*Individual SIMpull HEAD® model #'s begins with SPH.
 Visit www.southwiretools.com for full product listing.

**BUILT FOR DURABILITY.
 BUILT FOR RELIABILITY.
 BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.
 *Registered Trademark & ™Trademark of Southwire Company, LLC.