



Southwire™

ENT STUBBY

FEATURES

- Threaded
- Impact resistant
- Concrete tight, requiring no solvent welding or tape around the connections
- Rated for 175 lbs pull out resistance
- Approved for use in noncombustible 2 hour and 4 hour fire-rated floor/ceiling assemblies
- Meets all UL and CSA requirements

APPLICATION


- For use with Southwire ENT Flexible Conduit in residential, commercial or institutional applications

STANDARD MATERIAL

- Impact resistant PVC



1632

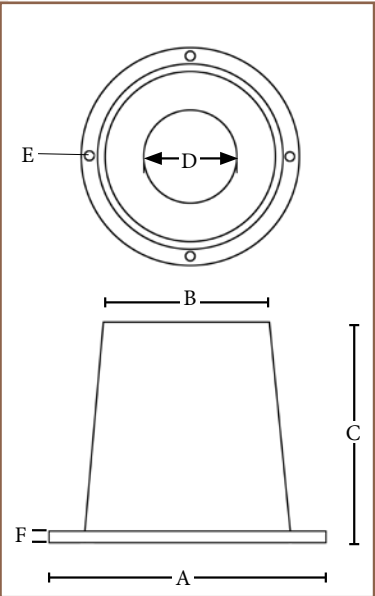

PART #	SIZE	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C	D	E	F
1631	1/2"	150	4	2.48"	1.45"	1.60"	.84"	.12"	.08"
1632	3/4"	150	7	2.48"	1.45"	1.60"	1.05"	.12"	.08"
1633	1"	200	14	3.64"	2.15"	1.60"	1.32"	.12"	.08"

Rev. 0, 03/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.