

LED Full Cutoff Wall Pack

POWER & CCT SELECTABLE



Make a Great First Impression

Topaz's LED Full Cutoff Wall Packs enhance the aesthetic of building exteriors by reducing glare, optimizing light and maximizing fixture spacing with a wide beam that evenly distributes light downward and outward. Designed with three wattage and three color temperature selections, the Full Cutoffs offer up to nine different configurations. The integrated dusk-to-dawn photocell automatically turns on or off, conserving energy during the day. Built to withstand harsh outdoor elements, these wall packs also feature a durable aluminum housing with four NPT 1/2" threaded hubs for additional accessories or conduit.

FEATURES

- Choose from three wattage and three CCT choices for up to nine possible configurations
- Die cast aluminum housing with IK10 rated impact resistant polycarbonate lens
- Integrated dusk-to-dawn photocell
- Four NPT 1/2" threaded hubs
- Meets the Dark Sky requirements when CCT is set to 3000K

SUGGESTED APPLICATIONS

- Commercial and residential
- Security lighting
- Perimeter lighting
- Warehouses
- Condos / apartments
- Hotels



LED Full Cutoff Wall Pack POWER & CCT SELECTABLE

GENERAL SPECIFICATIONS

Input Voltage, Frequency: 120-277V, 50/60Hz
Power Factor, THD %: >0.9, <20%
Dimming: 0-10V down to 10%¹
Efficacy: Up to 140 LPW
Minimum CRI: 84
IES Distribution: Type III
Functional Life (L70): 50,000 hours
Location Rating: Wet
IP Rating: IP65
IK Rating: IK10
Ambient Operating Temperature: -40°F to 113°F



**Integrated dusk-to-dawn
photocell***

ITEM SPECIFICATIONS / ORDER INFO

Catalog Number	Order Code	UPC	Lumens	Wattage	Input Current @120V/277V	CCT	DLC Premium ID*
WPFC-75W-PCTS-BZ-PC	72744	751338040014	6,310	45W	0.41A/0.18A	3000K	PL1UCBBOJ1MD
			7,930	60W	0.55A/0.24A	4000K	
			10,000	75W	0.69A/0.30A	5000K	

NOMENCLATURE

Example: **WPFC-75W-PCTS-BZ-PC**


WPFC = Wall Pack Full Cutoff - **75W** = 75 Watt - **PCTS** = Power and Color Selectable - **BZ** = Bronze - **PC** = Photocell

ENERGY SAVINGS

Catalog Number	LED Wattage	HID Replacement Wattage	Watts Saved	Yearly Savings	5 Year Savings
Based on 12 hours/day and \$0.11/kWh WPFC-75W-PCTS-BZ-PC	45W	135W	90W	\$43	\$217
	60W	180W	120W	\$58	\$289
	75W	225W	150W	\$72	\$361

DIMENSIONS / WEIGHTS

Catalog Number	(A)	(B)	(C)	Weight
WPFC-75W-PCTS-BZ-PC	5.10"	12.61"	6.86"	5.4 Lbs.

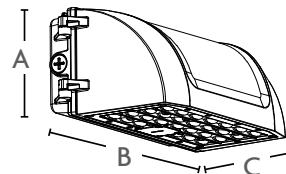

NOTES:

*Photocell can easily be disabled (bypassed) by user. Refer to product installation instructions for details.

*DLC Primary Use Designation: Outdoor Full-Cutoff Wall-Mounted Area Luminaires

¹Dimming with standard 0-10V control system or wall dimmers. Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Dimming performance may vary based on selected dimmer. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Specifications subject to change without prior notice. Replacement wattage shown depends on application and fixture.