



Southwire™

RIGID CONDUIT BODIES

THREADED LB TYPE - HOT DIP GALVANIZED

FEATURES

- Hot dip galvanized finish provides superior protection against severe environmental factors

APPLICATION

- Compatible with all Form 5 & Form 35 series conduit bodies and covers
- Provides taps for branch conduit runs
- Enables 90° bends in conduit runs

STANDARD MATERIAL

- Malleable iron

STANDARD FINISH

- Hot dip galvanized

CERTIFICATIONS


- UL Standard: UL 514A and UL 514D
- Fed. Spec: W-C-586D, A-A-50563
- NEMA: FB 1



LB1MHDG



Conforms to finish thickness ASTM A123/123M

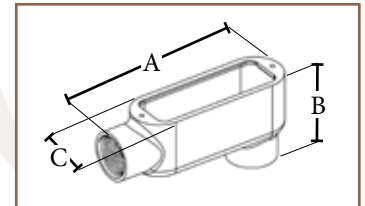

PART #	SIZE	WIRE SIZE		INTERNAL VOLUME (IN ³)	MASTER QTY.	WEIGHT/CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
LB1MHDG	1/2"	---	---	4.5	10	7	4.69"	2.18"	1.36"
LB2MHDG	3/4"	3	6 AWG	7.5	10	9	5.42"	2.36"	1.57"
LB3MHDG	1"	3	4 AWG	12.5	5	6	6.28"	2.86"	1.79"
LB4MHDG	1-1/4"	3	2 AWG	32.3	5	12	8.12"	3.49"	2.52"
LB5MHDG	1-1/2"	3	1/0 AWG	35.3	2	11	8.15"	3.69"	2.52"
LB6MHDG	2"	3	4/0 AWG	73	1	6	10.53"	4.52"	3.15"
LB7MHDG	2-1/2"	3	300 MCM	142	1	10	13.76"	5.39"	4.45"
LB8MHDG	3"	3	400 MCM	173	1	13	13.82"	6.18"	4.45"
LB9MHDG	3-1/2"	3	500 MCM	300	1	22	16.65"	7.19"	5.53"
LB10MHDG	4"	3	500 MCM	328	1	24	16.65"	7.36"	5.53"

Rev. 0, 05/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.