



LED A19 LAMP

SUGGESTED APPLICATIONS

- Residential, commercial, hospitality
- General lighting
- Task lighting
- Fan Lights
- Decorative

FEATURES

- Up to 85% energy savings
- Shatter resistant plastic lens with E26 base
- Suitable for use in enclosed fixtures



INPUT VOLTAGE: 120V

 
FREQUENCY: 50/60Hz

EFFICACY: UP TO 107 LPW

CRI: 80

BEAM ANGLE: 230°

**LIFETIME (L70):
UP TO 15,000 HOURS**



**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED A19 LAMP

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	LUMENS	WATTAGE	INPUT CURRENT	CCT
LA19-9W-827	75856	032886310737	750	9W	116mA	2700K
LA19-9W-830	75857	032886310744	750	9W	116mA	3000K
LA19-9W-840	75858	032886310751	750	9W	116mA	4000K
LA19-9W-850	75859	032886310768	750	9W	116mA	5000K
LA19-9W-865	75860	032886310775	750	9W	116mA	6500K
LA19-14W-827	75861	032886310782	1,500	14W	200mA	2700K
LA19-14W-830	75862	032886310799	1,500	14W	200mA	3000K
LA19-14W-840	75863	032886310805	1,500	14W	200mA	4000K
LA19-14W-850	75864	032886310812	1,500	14W	200mA	5000K

ORDERING GUIDE

Example: LA19-xW-8xx


PRODUCT	WATTAGE	CRI	CCT
LA19 = LAMP A19	9W 14W	80	2700K 3000K 4000K 5000K 6500K

ENERGY SAVINGS *Based on 12 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	INCANDESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LA19-9W-8XX	9W	60W	51W	\$25	\$123
LA19-14W-8XX	14W	100W	86W	\$41	\$207

DIMENSIONS | WEIGHT

MODEL #	A (IN)	B (IN)	WEIGHT (LBS.)
LA19-9W-8XX	4.09	2.36	0.5
LA19-14W-8XX	4.09	2.36	0.7

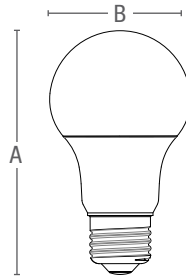

NOTES

Not for Sale in California

FIVE (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>

Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.



800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.