



# Mini-Roll

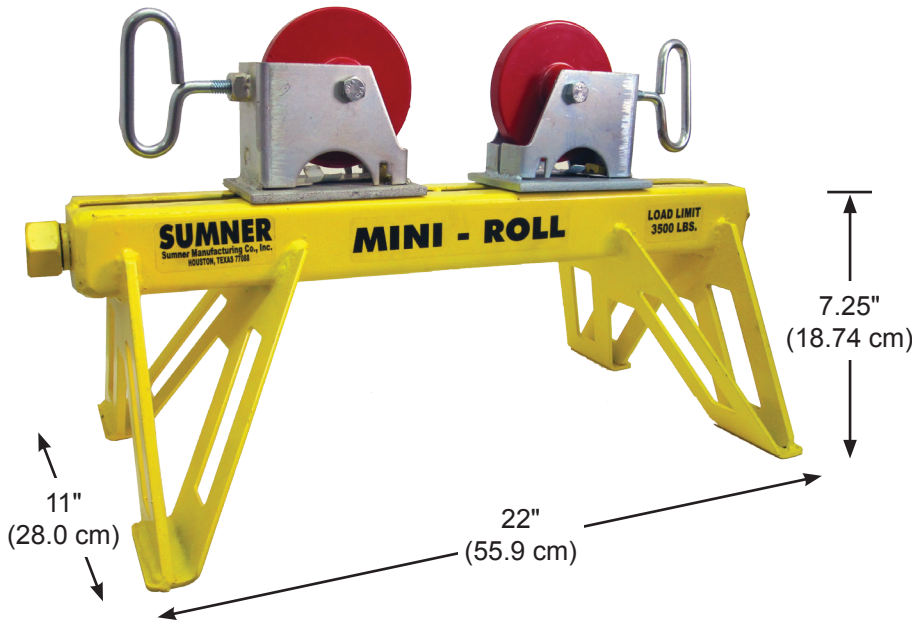


- ✓ ½ to 36" (1.2 to 91 cm) pipe capacity
- ✓ 3,500 lb (1580 kg) weight capacity
- ✓ Roller adjusts from either side
- ✓ Quick Change Roller Heads
- ✓ Brake to lock loads for layout
- ✓ No need for wedges


Mini-Roller - 7.25" (18.4 cm)		Weight	
Part No.	Description	lb	kg
785280	Mini Roll w/Roller Wheels	23.0	10.4
785281	Mini Roll w/Ball Transfer Heads	22.0	10.0
785282	Mini Roll w/Rubber Wheels	22.0	10.0
785283	Mini Roll w/Roller Wheels	23.0	10.4
785284	Mini Roll w/Bar Stock Head	31.0	14.1
785288	Mini Roll w/S.S. Ball Transfer Heads	23.0	10.4
785285	Mini Roll - Base Only	15.0	6.8

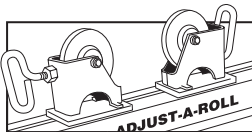


**Carbon Steel or  
Stainless Steel  
Roller Head**  
3,500 lb (1580 kg) capacity

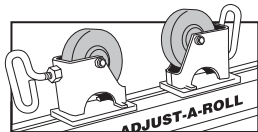

 **Rubber Wheel  
Roller Head**  
1,200 lb (550 kg) capacity



 **Ball Transfer  
Roller Head**  
1,000 lb (450 kg) capacity  
carbon or stainless steel balls



**Bar Stock Head**  
2,000 lb (900 kg) capacity  
Two position roller for  
containment or non-  
containment of material



Sumner Manufacturing Co., Inc.  
www.sumner.com

Part No.	Description	Weight	
		lbs	kg
783151	Q.C.R.H. w/roller wheels	8.0	3.6
783152	Q.C.R.H. w/rubber wheels	7.0	3.2
783153	Q.C.R.H. w/roller wheels	8.0	3.6
783154	Q.C.R.H. w/ball transfer head	7.0	3.2
783155	Q.C.R.H. w/bar stock head	16.0	7.2
783159	Q.C.R.H. w/stainless steel ball transfer head	8.0	3.6

Sumner - U.S. 7514 Alabonson Road • Houston, TX 77088 • Ph: 281-999-6900 • Fax: 281-999-6966

Sumner - Canada 75 Saltsman Drive, Unit 5 • Cambridge, Ontario N3H 4R7 • Ph: 519-653-5300 • Fax: 519-653-5305

Sumner - Netherlands Midden Engweg 21 • NL-3882TS Putten • The Netherlands • Ph: +31 (0) 85 489 0284 • europeansales@sumner.com

Sumner - U.K. Unit 3 Kempton Road • Keytec 7 Business Park • Pershore, Worcestershire WR10 2TA • Ph: (44) 01386 556278 • Fax: (44) 01386 556776