



# LED EXIT SIGNS - NYC APPROVED

## EDGE-LIT UNIVERSAL MOUNT

### SUGGESTED APPLICATIONS

- Emergency lighting for office, industrial, retail and other public spaces
- New York City applications

### FEATURES

- Universal mounting with recessed and surface mount hardware included
- Adjustable galvanized steel hanger bars included for recessed mount assembly
- Mounting canopy included for surface, ceiling and wall mount options
- Extruded brushed aluminum housing with high grade acrylic panel
- Red EXIT letters - 8" height and 1" stroke
- 120/277V dual voltage operation
- Ni-Cad battery backup for 90 minutes of emergency illumination
- Test switch and AC supply indicator
- Configurable chevron directional arrows
- 100FT viewing distance rating UL924 Standard
- Available in two panel options single face clear or double face mirror insert
- Meets NFPA 70, NFPA 101, UL924, NEC and OSHA standards

**FREQUENCY: 60Hz**

**ENERGY USED IN  
MAINTENANCE MODE:  
AC SUPPLY**

**RECHARGE TIME: 24 HOURS**

**EMERGENCY DURATION /  
RUN TIME: 90 MINUTES**

**MOUNTING HEIGHT:  
7.5FT TO 15 FT**

**RECYCLE TIMES: 500 CYCLES**



 
**RECESSED**



**SURFACE MOUNT  
SHOWN**



**MOUNTING ACCESSORIES  
INCLUDED**



**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

**800-666-2852 | SOUTHWIRE.COM**

©2024 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.



# LED EXIT SIGNS - NYC APPROVED

## EDGE-LIT UNIVERSAL MOUNT

### ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	INPUT VOLTAGE	WATTAGE	LUMINANCE (AVG)	LETTER COLOR	PANEL TYPE	NUMBER OF FACES
ESEL/SFR/RCL/B-NYC	71101	751338035768	120/277V	3W	Avg. 41 cd/m2	Red	Clear	Single Face
ESEL/DFR/RMR/B-NYC	71102	751338035782	120/277V	3W	Avg. 36 cd/m2	Red	Mirrored	Double Face

### ORDERING GUIDE



EXAMPLE: ESEL/SFR/RCL/B-NYC

PRODUCT	NUMBER OF FACES	MOUNT TYPE	LETTER COLOR	PANEL TYPE	OPTION
ESEL = Exit Sign Edgelit	SF = Single Face DF = Double Face	R = Recessed	R = Red	CL = Clear MR = Mirrored	B = Battery Backup NYC = NYC Approved

### DIMENSIONS | WEIGHT

MODEL #	WEIGHT (LBS) (2 DECIMALS)	PALLET QUANTITY (PCS)* 48"X40"X60"
ESEL/SFR/RCL/B-NYC	5.5	96
ESEL/DFR/RMR/B-NYC	5.5	96

\*pallet qtls may vary

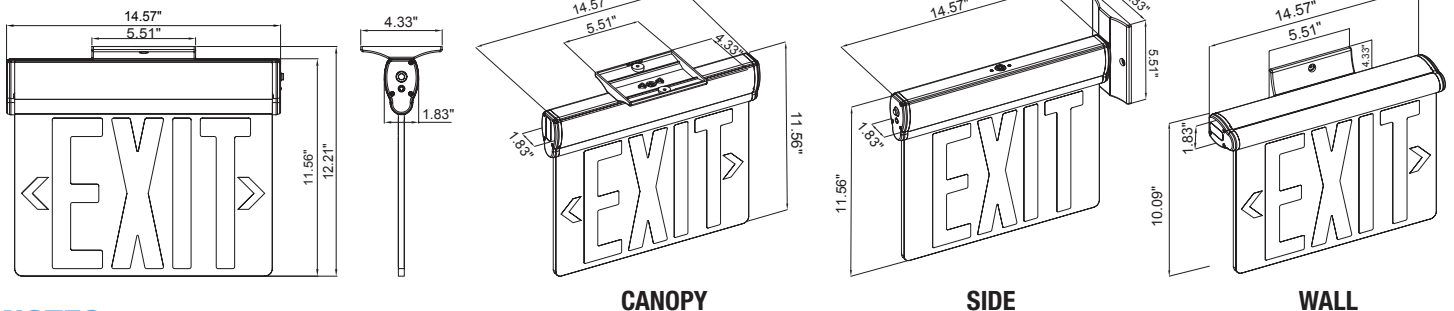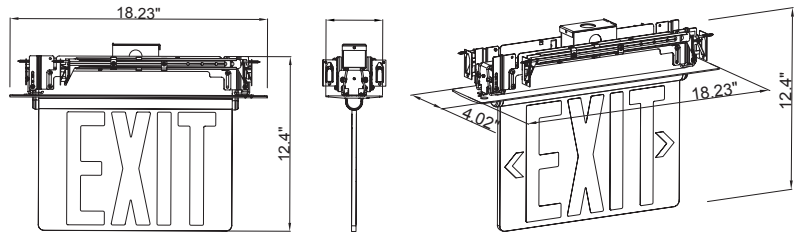

### NOTES

<sup>1</sup> On all exit and emergency fixtures battery will be prorated for 5 years.  
 Five (5) YEAR LIMITED WARRANTY: SOUTHWIRE COMPANY, LLC. For details visit: <https://southwire.com/resources/warranties>  
 This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.  
 CAN-ICES-003B/NMB-003B.  
 Specifications are subject to change without prior notice. Replacement wattage shown depends on application and fixture.



800-666-2852 | SOUTHWIRE.COM

©2024 Southwire Company, LLC. All rights reserved.  
 \*Registered Trademark & ™Trademark of Southwire Company, LLC.