


FLANGE SPREADER™

FEATURES

- 4 models to cover flange ranges from 1" (25 mm) to 24" (600 mm)
- Can be used for 150 to 1,500 lbs flanges
- Hardened wedge for safe splitting
- Large feed screw
- Drive can be rotated by 1-3/8" wrench or 1/2" (12 mm) bar
- Compact design – strong enough for tough jobs

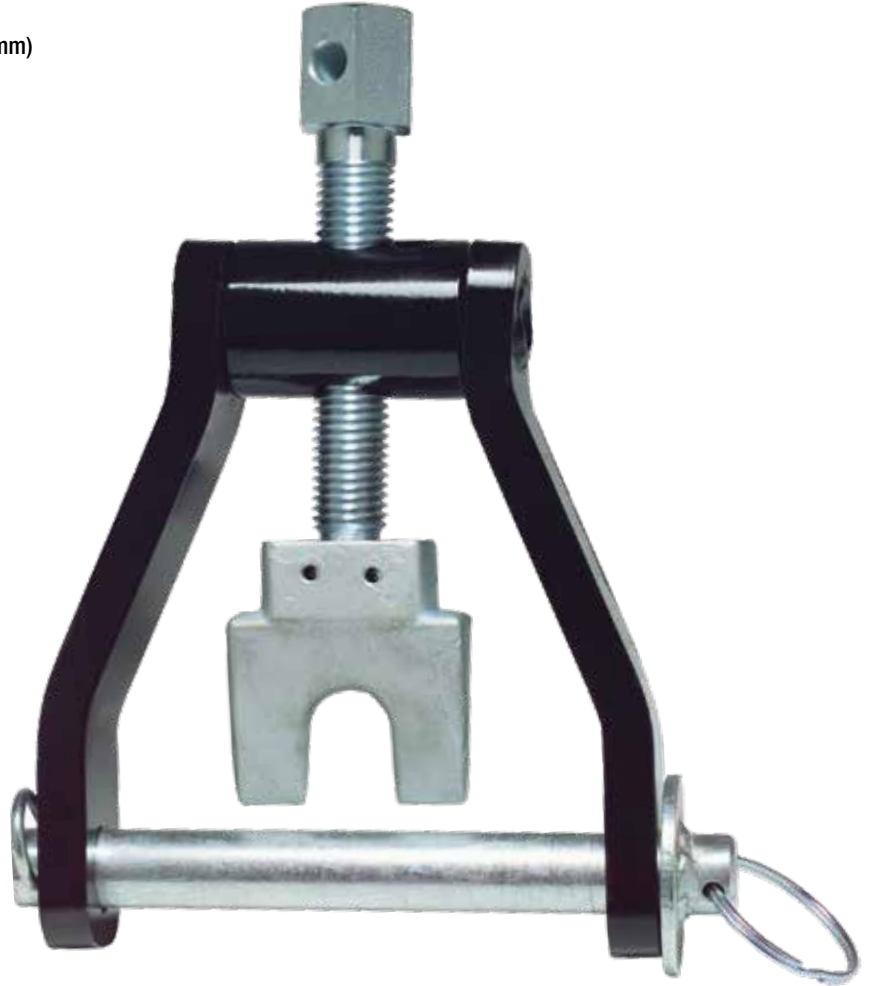

ITEM #	DESCRIPTION	MODEL #	UPC	SPREAD	PIN DIAMETER	FLANGE CLASS					
						150 LBS	300 LBS	400 LBS	600 LBS	900 LBS	1,500 LBS
784003	3" Flange Spreader	ST-301	661165840032	3"	5/8"	1"-6"	3/4"-4"	1/2"-2"	-	-	-
784002	4" Flange Spreader	ST-302	661165840025	4"	3/4"	2"-12"	1 1/2"-8"	1"-4"	1"-4"	1"-2"	1"-2"
784001	5" Flange Spreader	ST-303	661165840018	5"	7/8"	5"-24"	2-1/2"-12"	1-1/2"-8"	2"-6"	1"-4"	1"-3"
784000	6-3/8" Flange Spreader	ST-304	661165840001	6-3/8"	1"	10"-24"	7"-24"	3-1/2"-16"	4"-10"	1"-8"	1"-5"