




# PROLIGHT™

## PROLIGHT™ SLIM SERIES EXTREME - 150W, 220W, 300W

The newest addition to the ProBuilt floodlight category are the Slim Series Extreme! With three high wattages of 150w, 220w and 300w, these lights are energy efficient and have a high-output of Lumens topping out at 37,000! Due to the extreme slim design and the cool operation these lights can be used in confined spaces. The new lights are also designed for permanent installation or long-term temporary use outdoors. The ProLight™ Slim Series Extreme can keep the job site safe and bright while drawing minimal amps, providing the ultimate energy savings. Tested and rated to the highest standards, the ProLight™ Slim Series Extreme is cUL listed for wet locations and has an IP65 rated housing. Developed for the professional tradesman, the aluminum and steel construction make the ProLight™ Slim Series Extreme durable enough for the harshest conditions.

### 150 WATT

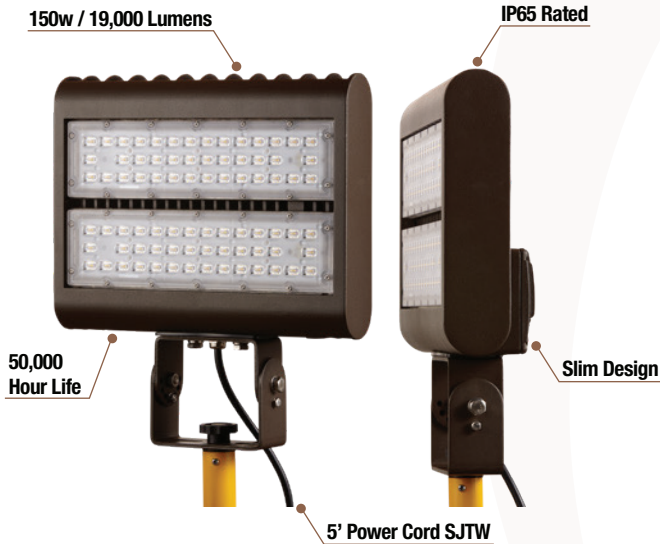

### 220 WATT / 300 WATT



Model No	Luemens	Lighting Range	Bulb Tyoe	Lamp Life (hrs)	Kelvins	Watts	Amp Draw	Voltage	Temp Rated	Tested	Cord Type	Weight	IP Rating
4110150	19,000	70ft	LED	50,000 hrs	5,000	150	1.36	100-277	-40°-105°F	cUL	18/3 SJTW	12.2 lbs	65
4110220	29,000	90ft	LED	50,000 hrs	5,000	220	2	100-277	-40°-105°F	cUL	18/3 SJTW	17.2 lbs	65
4110300	37,000	120ft	LED	50,000 hrs	5,000	300	2.7	100-277	-40°-105°F	cUL	18/3 SJTW	19.7 lbs	65

BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™

1-855-798-6657 | SOUTHWIRETOOLS.COM

©2018 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.